

# Fixed tube carrier



## NPTF20

### For Ø10 to Ø14 tubes

- For round or square tubes

- Materials:



Body: reinforced polyamide

Screws: stainless steel

### Info.

- Not sold individually, please contact us for details

 Detail X

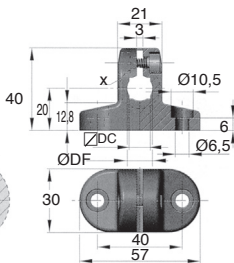

### DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	Ø DF	∅ DC	Weight (kg)	Stock*	Price each 1 to 29
NPTF20-10	10	8	0,03	✓	5,64 €
NPTF20-12	12	10	0,03	✓	5,64 €
NPTF20-14	14	12	0,03	✓	6,26 €

\*Depending on availability - Dimensions in mm

## NPTF20 ENT


# Spacer for tube carrier

Plastic




- Material: reinforced polyamide

### Info.

- Not sold individually, please contact us for details

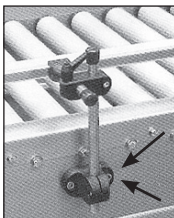

Typical application

 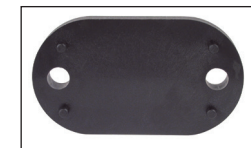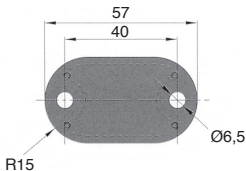

### DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	H	Weight (kg)	Stock*	Price each 1 to 29
NPTF20-ENT4	4	0,01	✓	2,98 €
NPTF20-ENT6	6	0,02	✓	2,98 €

\*Depending on availability - Dimensions in mm

## Our other products



SH3

Parallel axis helical gear, Steel 20NCD2



T39\_T49

Extension spring in metre length stainless steel, by the metre



RPCpl

Swivel castor with double brake, Steel - Polyamide



MLY

Bow shackle with eye bolt, Steel



GPLbr

Brush, brass



HTD8M\_20

HTD Heavy duty timing pulley, HTD8 Steel



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel



CHTRP

Single and dual output gearboxes, Up to 87,3Nm



VRC1

Retaining clamp, single sided, Single



LR

Precision locknut, Precision locknut



DBL805

Idler for slat top chain, Range 805



SLB

Indexing plunger, steel class 5.8

## Complementary products



NPTF20

Spacer for tube carrier, Fixing accessory  $\varnothing 10$  to  $\varnothing 14$



APB\_T

Adjusting rod for clamp - Female, Bored