

Fixed tube carrier



NPTF20

For Ø10 to Ø14 tubes

- For round or square tubes

- Materials:



Body: reinforced polyamide

Screws: stainless steel

Info.

- Not sold individually, please contact us for details

 Detail X

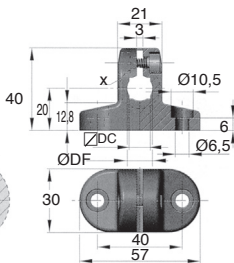

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	Ø DF	∅ DC	Weight (kg)	Stock*	Price each 1 to 29
NPTF20-10	10	8	0,03	✓	5,64 €
NPTF20-12	12	10	0,03	✓	5,64 €
NPTF20-14	14	12	0,03	✓	6,26 €

*Depending on availability - Dimensions in mm

NPTF20 ENT


Spacer for tube carrier

Plastic




- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

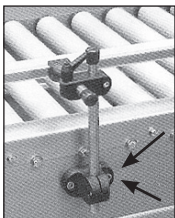

Typical application

 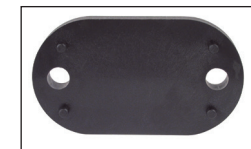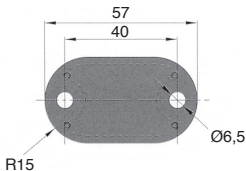

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	H	Weight (kg)	Stock*	Price each 1 to 29
NPTF20-ENT4	4	0,01	✓	2,98 €
NPTF20-ENT6	6	0,02	✓	2,98 €

*Depending on availability - Dimensions in mm

Our other products



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



STRIP1000

Sealing brush strip, 1m length



PSPE22

Conical flexible shaft handlee Ø22, Black PVC



ZBRA

Machined plastic bevel gear, 1:1




CDGamme

Compression spring DIN2095, DIN 2095



GG1

 Ground spur gear, Heat treated steel



PRZ

Wear strip for slat top chain, Z profile to be clipped



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



CHM75

Worm and wheel gear reducer, up to 298 Nm



PDD

Actuating plunger, Non-rotating detector shaft



ETP

Modular handle for aluminium profile, Modular handle



M2

Worm and wheel set, Machined plastic (delrin)

Complementary products



NPTF20

Spacer for tube carrier, Fixing accessory Ø10 to Ø14



APB_T

Adjusting rod for clamp - Female, Bored