

- For round or square tubes


- Materials:

Body: reinforced polyamide

Screws: stainless steel

Accessories

- APB-F and APB-T
adjusting rods

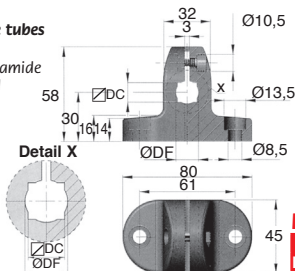

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	ØDF	ØDC	Weight (kg)	Stock*	Price each 1 to 29
NPTF30-14	14	12	0,09	✓	12,39 €
NPTF30-16	16	14	0,09	✓	12,39 €
NPTF30-18	18	16	0,09	✓	12,39 €
NPTF30-20	20	18	0,09	✓	12,39 €

*Depending on availability - Dimensions in mm

Spacer for tube carrier

Plastic


NPTF30

ENT


- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

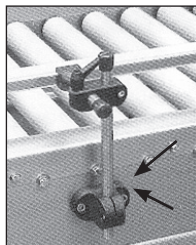

Typical application

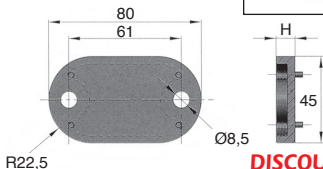

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	

Part number	H	Weight (kg)	Stock*	Price each 1 to 29
NPTF30-ENT10	10	0,03	✓	3,15 €

*Depending on availability - Dimensions in mm

Our other products



BTE

Universal tension arm,
For standard
applications



SLBW

Indexing plunger,
weldable, Weldable -
Steel



 
BEAS

Star shaped anti-
static handle, Star,
anti-static




SBRtool

Chain tool, Drive
chain maintenance
tools



H0

 Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



PF40

Worm and wheel gear
reducer, up to 18 Nm



CDGamme

Compression spring
DIN2095, DIN 2095



GG3

Ground spur gear,
Heat treated steel



QNU

Single row cylindrical
roller bearing, Free



NIN

Self-locking nut, A2
Stainless steel



MACss

Stainless steel
carabiner, Stainless



SSDB

Stainless steel bevel
gear, 2:1

Complementary products



NPTF30

Fixed tube carrier,
Fixed Ø14 to Ø20



APB_T

Adjusting rod for
clamp - Female, Bored