

- For round or square tubes


- Materials:

Body: reinforced polyamide

Screws: stainless steel

Accessories

- APB-F and APB-T
adjusting rods

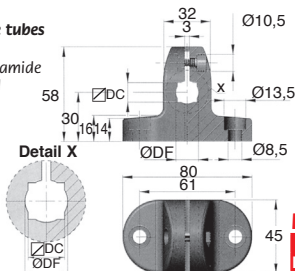

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	On request

Part number	ØDF	ØDC	Weight (kg)	Stock*	Price each 1 to 29
NPTF30-14	14	12	0,09	✓	12,39 €
NPTF30-16	16	14	0,09	✓	12,39 €
NPTF30-18	18	16	0,09	✓	12,39 €
NPTF30-20	20	18	0,09	✓	12,39 €

*Depending on availability - Dimensions in mm

Spacer for tube carrier

Plastic


NPTF30

ENT



- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

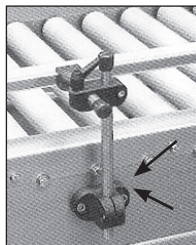

Typical application

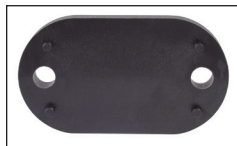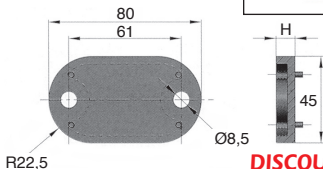

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	On request

Part number	H	Weight (kg)	Stock*	Price each 1 to 29
NPTF30-ENT10	10	0,03	✓	3,15 €

*Depending on availability - Dimensions in mm

Our other products



PR40

Articulated foot Ø50,
Ø 50



PTAf80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80



ACLEPP

Right angled bracket
for aluminium profile,
4 holes



PSG08

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



ACM_TRI

Manual bonnet
fastener, Black rubber
fastener



PML

Solid foot mount for
heavy loads, Ø 100,
120 or 150



ALIDRP240

24V DC power supply,
10 A



GG1

Ground spur gear,
Heat treated steel



H02

Single needle roller
universal joint, Heavy
duty



HRV

V- rail guidance
Simple Select®
system, Rail with



T5M T10M

T type timing belt per
metre, T10 Steel
cored polyurethane



CABma

Swaging sleeve for
fitting cable, To crimp
a wire rope

Complementary products



NPTF30

Spacer for tube
carrier, Fixing
accessory Ø14 to Ø20



APB_T

Adjusting rod for
clamp - Female, Bored