

- For round or square tubes


- Materials:

Body: reinforced polyamide

Screws: stainless steel

Accessories

- APB-F and APB-T
adjusting rods

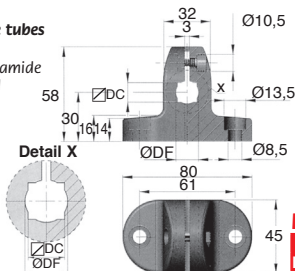

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|-------|----------|------|------------|-----|
| Disc. | List -5% | -10% | On request | |

| Part number | ØDF | ØDC | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|-----|-----|-------------|--------|--------------------|
| NPTF30-14 | 14 | 12 | 0,09 | ✓ | 12,39 € |
| NPTF30-16 | 16 | 14 | 0,09 | ✓ | 12,39 € |
| NPTF30-18 | 18 | 16 | 0,09 | ✓ | 12,39 € |
| NPTF30-20 | 20 | 18 | 0,09 | ✓ | 12,39 € |

*Depending on availability - Dimensions in mm

Spacer for tube carrier


Plastic

NPTF30 ENT


- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

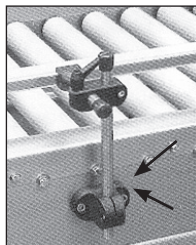

Typical application

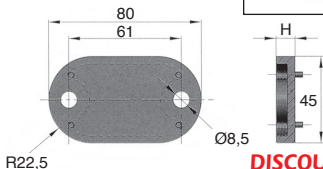

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|-------|----------|------|------------|-----|
| Disc. | List -5% | -10% | On request | |

| Part number | H | Weight (kg) | Stock* | Price each 1 to 29 |
|--------------|----|-------------|--------|--------------------|
| NPTF30-ENT10 | 10 | 0,03 | ✓ | 3,15 € |

*Depending on availability - Dimensions in mm

Our other products



PFM

Pressed steel foot,
Flanged plate



HS

Spacer, Stainless steel
303



RMSA

Shock Absorber,
Adjustable



HLA24

Right angle bevel
gearbox, Up to 78Nm



RJA11_27

Linear sealing strip,
Not clipping



BCM_MPBT

Modular cylindrical
brush, PBT polyester
bristles



FB_ECO

Bevel gear - Steel
C43, 4:1



ACL-FPA

Panel accessories,
Support block



EML

Star knob, Lobed
handscrew



AC

Catch plate for toggle
latch, 15mm



FB_ECO

Bevel gear - Steel
C43, 4:1



E30

Angle transmission
gearbox, from 1.50 to
9 Nm

Complementary products



NPTF30

Fixed tube carrier,
Fixed $\varnothing 14$ to $\varnothing 20$



APB_T

Rod for clamp, Bored