





- For  $\text{Ø}14$  to  $\text{Ø}20$  round tube
- Materials:  
Body: reinforced polyamide  
Screws: stainless steel

### Info.

- Not sold individually, please contact us for details

### Accessories

- APB-F and APB-T adjusting rods

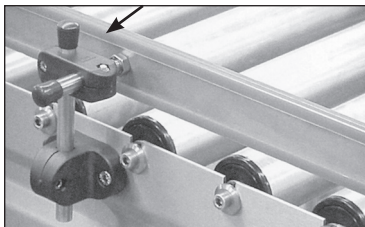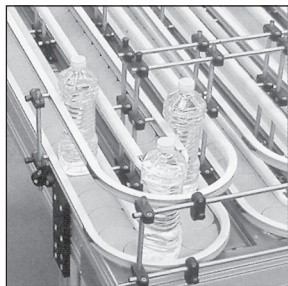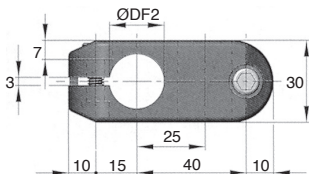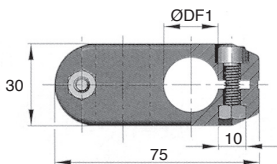

↑  
← Typical applications

### DISCOUNTS

Qty	1+	30+	40+	60+
Disc.	List	-5%	-10%	On request

Part number	ØDF1	ØDF2	Weight (kg)	Stock*	Price each 1 to 29
NPTR14-14	14	14	0,07	✓	6,45 €
NPTR14-15	14	15	0,07	-	6,45 €
NPTR14-16	14	16	0,07	-	6,45 €
NPTR15-15	15	15	0,07	-	6,45 €
NPTR15-16	15	16	0,07	-	6,45 €
NPTR16-16	16	16	0,07	✓	6,45 €
NPTR18-18	18	18	0,07	✓	6,45 €
NPTR20-20	20	20	0,07	✓	6,45 €

\*Depending on availability - Dimensions in mm

## Our other products



SA\_SAKH  
Housing for linear bearing, Closed - light load



CDR  
Retaining cable for ball pin, Retaining cable




CHAR  
Spring hinge, screwed



KB\_UU  
Closed linear precision bearing, Precision - steel



 WJUM20  
Drylin® W bearing block, Slide



H0  
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



CAP881  
Side flexing slim slat top chain stainless steel, Narrow range 881



VDSQCB  
Sliding lock adjustment system, Blocking wedge




PCS50SS  
Chain sprocket - Stainless steel,



PCS62SS  
Chain sprocket - Stainless steel,



 DBL805  
Idler for slat top chain, Range 805



T0  
Torsion spring, Stainless steel

## Complementary products



APB\_F  
Adjusting rod for clamp - Male, Threaded



APB\_T  
Adjusting rod for clamp - Female, Bored



NSA  
Adjustable clamp, Articulated