

# Adjustable cross clamp




## NPTR<sub>M</sub>

## Quick adjustment


- For Ø14 to Ø20 round tube
- Materials:
  - Body: reinforced polyamide
  - Screws: stainless steel
  - Thread inserts: zinc plated steel

### Accessories

- APB-F and APB-T adjusting rods

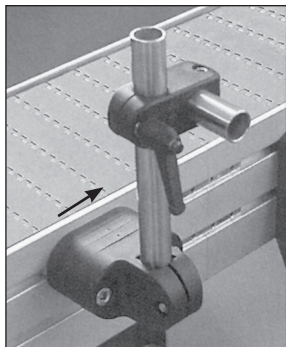

Typical application

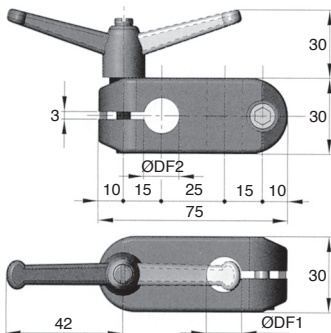

### DISCOUNTS

Qty	1+	30+	40+	60+
Disc.	List	-5%	-10%	On request

Part number	ØDF1	ØDF2	Weight (kg)	Stock*	Price each 1 to 29
NPTR14-14/M	14	14	0,09	✓	17,12 €
NPTR15-15/M	15	15	0,09	✓	17,12 €
NPTR16-16/M	16	16	0,09	✓	17,12 €
NPTR18-18/M	18	18	0,09	-	17,12 €
NPTR20-20/M	20	20	0,09	✓	17,12 €

\*Depending on availability - Dimensions in mm

## Our other products



SSDB  
Stainless steel bevel gear, 2:1



RJUM05  
Drylin R® linear bearing housing, Closed - Long



J51  
Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - In-line



WS16  
Drylin® W rail, Rail



PLS  
Cylindrical spacer, Stainless steel 303



PVL  
Small lobed handle, Polyamide



RJA00\_02  
Sealing strip, Clipping



PR85  
Articulated foot Ø83, Ø 83



BABFCFO  
Ball pin socket, Mounting collar with an oval flange



SH4  
Parallel axis helical gear, Steel 20NCD2



SSB  
Stainless steel bevel gear, 1:1



ADL\_M  
Male eye bolt conforms to DIN580, Stainless steel

## Complementary products



APB\_T  
Adjusting rod for clamp - Female, Bored



APB\_F  
Adjusting rod for clamp - Male, Threaded



PCP  
Cell carrier assembly, Ready assembled