

Adjustable cross clamp



NPTR_M


Quick adjustment

- For Ø14 to Ø20 round tube
- Materials:
Body: reinforced polyamide
Screws: stainless steel
Thread inserts: zinc plated steel


Accessories

- APB-F and APB-T adjusting rods

Quick adjustment

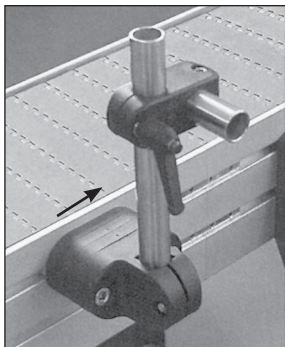

Typical application

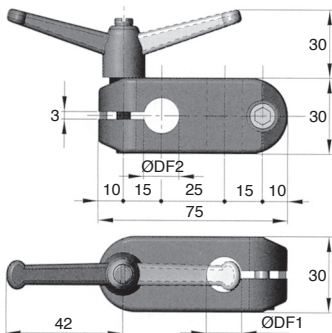

DISCOUNTS

Qty	1+	30+	40+	60+
Disc.	List	-5%	-10%	On request

Part number	ØDF1	ØDF2	Weight (kg)	Stock*	Price each 1 to 29
NPTR14-14/M	14	14	0,09	✓	17,12 €
NPTR15-15/M	15	15	0,09	✓	17,12 €
NPTR16-16/M	16	16	0,09	✓	17,12 €
NPTR18-18/M	18	18	0,09	-	17,12 €
NPTR20-20/M	20	20	0,09	✓	17,12 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



NTMbr
Set screw brass tip,
Brass-point



PM4
Worm and wheel set,
Bronze



DIA
Ring operated locking
bolt, with ring



RTE
Rotex®, jaw coupling,
steel



T2
T type timing belt,
T2.5 Steel cored
polyurethane



BABss
303 Stainless steel
ball pin, 303 Stainless
steel



PV2R
Adjustable suction-
cup support,
Increased grip



VDSQCB
Sliding lock
adjustment system,
Blocking wedge



PRF_T
Corner reinforcement,
Corner reinforcement



F7-P-AM
Multifunction display,
Magnetic band



CFS
Miniature cam
follower, Miniature



MC
Self-compensating
shock-absorber, Self-
compensating -
without adjust...

Complementary products



APB_F
Adjusting rod for
clamp - Male,
Threaded



APB_T
Adjusting rod for
clamp - Female, Bored



NSA
Adjustable clamp,
Articulated



PCP
Cell carrier assembly,
Ready assembled