

Adjustable cross clamp



NPTR

Standard version for 10mm + 12mm rods


- For $\varnothing 10 + \varnothing 12$ round tubes or 8mm + 10mm square rods

- Materials:

Reinforced polyamide / Screws: stainless steel

Info.

- Not sold individually,
please contact us for details

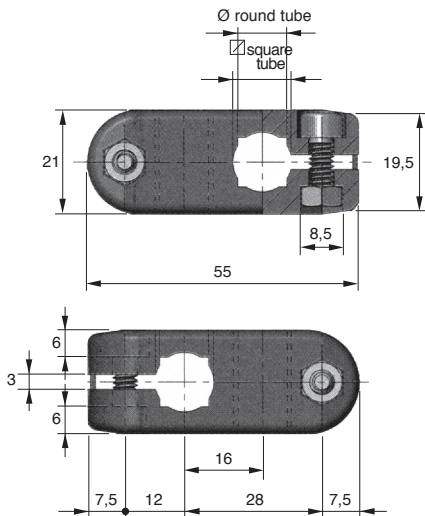

DISCOUNTS

Qty	1+	30+	40+	60+
Disc.	List	-5%	-10%	On request

Part number	\varnothing round tube	\square square tube	Weight (kg)	Stock*	Price each 1 to 29
NPTR10-10	10	8	0,03	✓	5,86 €
NPTR12-12	12	10	0,03	✓	5,86 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



SCA
Flat cable clamp,
Steel



PSG15S
Spur gear - precision
range, Stainless steel
316



M1
Worm and wheel set,
Non hardened steel



PRF_SDD_1820
Support for Ø18 or
Ø20mm Prox
detector, Ø18 and
Ø20



DOG316
Motor-gearbox 12V
and 24V DC, from 1.5
to 2 Nm



PM4
Worm and wheel set,
Non hardened steel



UGH50
H Type Guide units,
For Ø50 actuators



WBGV
Lifting ring, Threaded



ETGamme
Extension springs
DIN2097, DIN 2097



CHTRP
Single and dual
output gearboxes, Up



ACLBMC
Detector support for
aluminium profile,



BAC105
Storage bin, 8mm

Complementary products



APB_T
Adjusting rod for
clamp - Female, Bored



APB_F
Adjusting rod for
clamp - Male,
Threaded