

Adjustable cross clamp



NPTR

Standard version for 10mm + 12mm rods


- For $\varnothing 10 + \varnothing 12$ round tubes or 8mm + 10mm square rods

- Materials:

Reinforced polyamide / Screws: stainless steel

Info.

- Not sold individually,
please contact us for details

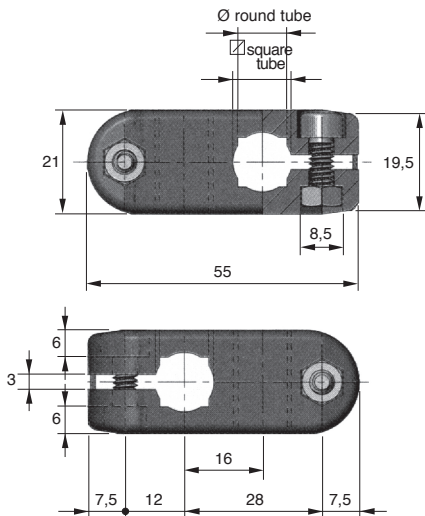

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	On request

Part number	\varnothing round tube	\square square tube	Weight (kg)	Stock*	Price each 1 to 29
NPTR10-10	10	8	0,03	✓	5,86 €
NPTR12-12	12	10	0,03	✓	5,86 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



P45

Worm and wheel gear reducer, up to 40 Nm



ACLBDB

Closing mechanism for aluminium profile, Dual ball catch



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm



PRF4590

Standard aluminium profile, 45 x 90 mm



PCS62SS

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)



RIMple

Locking castor, with mounting plate



FAD

Threaded swivel feet, Swivel feet without anti-slip plate



COA-COG

Surface mounting plate, Surface mounting plate for



VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...



NPTF20

Spacer for tube carrier, Fixing accessory Ø10 to Ø14

Complementary products



APB_T

Adjusting rod for clamp - Female, Bored



APB_F

Adjusting rod for clamp - Male, Threaded