

Adjustable cross clamp



NPTR

Standard version for 10mm + 12mm rods


- For $\varnothing 10 + \varnothing 12$ round tubes or 8mm + 10mm square rods

- Materials:

Reinforced polyamide / Screws: stainless steel

Info.

- Not sold individually,
please contact us for details

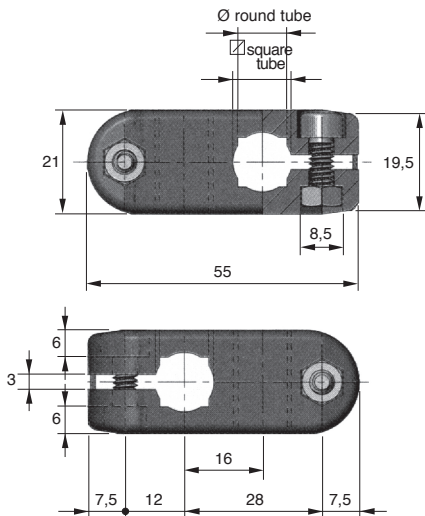

DISCOUNTS

Qty	1+	30+	40+	60+
Disc. List	-5%	-10%	On request	On request

Part number	\varnothing round tube	\square square tube	Weight (kg)	Stock*	Price each 1 to 29
NPTR10-10	10	8	0,03	✓	5,86 €
NPTR12-12	12	10	0,03	✓	5,86 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



ALIDRP240

24V DC power supply, 10 A



 
COA-COG

Surface mounting plate, Surface mounting plate for ball joint



GE

Toggle latches, Standard



T0

Torsion spring, Stainless steel



MRA

Quick link, Steel



CLR

Straight clevis, Straight clevis for use with a male clevis



D19 D29

Compression springs in metre length steel, by the metre



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body +



 
MHPGR

Arm with folding rotating handle,



PRF_GAL

Roller for aluminium profile, Flat roller



MRS

Stainless steel metric section rack, Stainless steel

Complementary products



APB_F

Adjusting rod for clamp - Male, Threaded



APB_T

Adjusting rod for clamp - Female, Bored



NSA

Adjustable clamp, Articulated