

Adjustable support clamp

Sta Stock

NRR

Easy to mount and adjust

- Support clamp with adjustable head

- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures


Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

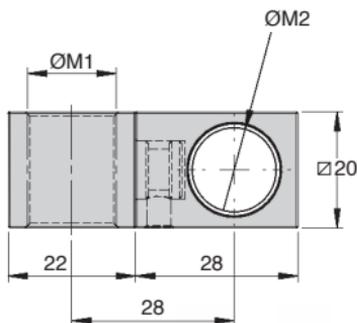

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRR8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	16,27 €
NRR8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	-	16,37 €
NRR8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	-	16,77 €
NRR10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	16,56 €
NRR10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	16,67 €
NRR12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	16,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RHTplss
High Temperature
Castor, up to 200kg



FF50
Offset spur gear
reducer, from 111 to
425 Nm



D-PAR_SS
Stainless steel elasto
mount, stainless steel



G-ECO25
Eco range Spur gear,
Steel C45



KBS_UU
Stainless steel closed
precision linear
bearing, Precision -
stainle...



MSP23
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
tapped ins...



SLB
Indexing plunger,
steel class 5.8



GPB
Threaded spherical
knob, With brass
insert



PTA80
Articulated levelling
foot, pressed base



PTAF100-PAMF100
Articulated fixable
foot with pressed
base



GGB
Female wing knob,
Fully threaded



FB_ECO
Eco. range steel bevel
gear, 4:1

Complementary products



APBC
Circular rod, Round
rod



MBF
Threaded blocking
clamp, Threaded
locking clamp