

Adjustable support clamp

Sta Stock

NRR

Easy to mount and adjust

- Support clamp with adjustable head

- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures


Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

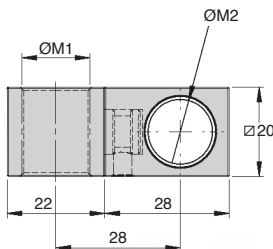

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRR8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	16,27 €
NRR8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	-	16,37 €
NRR8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	-	16,77 €
NRR10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	16,56 €
NRR10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	16,67 €
NRR12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	16,98 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PM2

Worm , Machined plastic (delrin)



SLB

Indexing plunger, steel class 5.8



BLH20

Right angled gearbox, from 0.53 to 1.77



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot



F7-SN

Multifunction display, Articulated support



gt64r

Rotating bent lever with spring, Increased fitting tolerances



VDS

Sliding lock adjustment system, Sliding lock for oblong hole



UTKpwr

Utilitrak® 3 wheels carriage, Polymer roller carriage



BAG

Steel Clamping collar, Steel



 
TS01_TW01

Drylin® T linear slide, up to 7000 N



RTT

Locking Assembly, Medium/high torque



CFC

Spring loaded position switch, Electric contact

Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp