

Adjustable support clamp

Sta Stock

NRR

Easy to mount and adjust

- Support clamp with adjustable head

- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures


Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

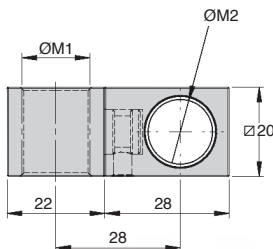


DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRR8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	16,27 €
NRR8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	-	16,37 €
NRR8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	-	16,77 €
NRR10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	16,56 €
NRR10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	16,67 €
NRR12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	16,98 €

*Depending on availability - Dimensions in mm

 
Our other products



Worm and wheel set,
Machined plastic
(delrin)



 Eco range Spur gear,
Steel C45



Guide for aluminium
profile, Parallel rails



End cap for square
tube, Standard



Retaining clamp,
single sided, Single
sided



Swivel castor with
plate, Steel - grey
rubber



Connecting kits, XY
linking kit



Machined plastic
bevel gear , 2:1



Skive hobbed spur
gears - precision



Extension spring in
metre length steel, by



Tapered roller
bearing, Steel



Linear table, For small
lengths

Complementary products



Circular rod, Round
rod



Threaded blocking
clamp, Threaded
locking clamp