

Adjustable support clamp

Sta Stock

NRR

Easy to mount and adjust

- Support clamp with adjustable head

- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures


Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

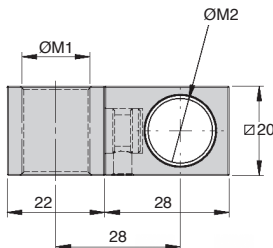

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request


Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRR8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	16,27 €
NRR8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	-	16,37 €
NRR8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	-	16,77 €
NRR10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	16,56 €
NRR10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	16,67 €
NRR12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	16,98 €

*Depending on availability - Dimensions in mm

Our other products




HW_HT
Half-rail guide, Wheel

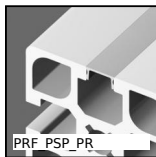

PRF_PSP_PR
Dual purpose strip and cover for aluminium profile, Inserts into slot



DOMI50
Domino 50 adjustable slide, Slide DOMILINE 50

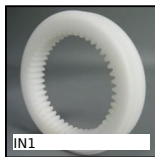

IN1
Internal gear, Machined plastic (delrin)




BLHM60
Right angled gearbox, double output shafts, up to 70 Nm



PM3
Worm and wheel set, Non hardened steel



 UGH20
H Type Guide units, For Ø20 actuators



JFM
Flanged polymer bush, Universal polymer



 
SDG
Adjustable guide support bracket, Plastic



PW_PWG15
Worm - precision range, Steel



S20
Short housing for open linear bearing, Opened - slim



M0
Worm and wheel set, Machined plastic (delrin)

Complementary products



APBC
Circular rod, Round rod



MBF
Threaded blocking clamp, Threaded locking clamp