

Adjustable support clamp

Sta Stock

NRR

Easy to mount and adjust

- Support clamp with adjustable head

- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures


Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

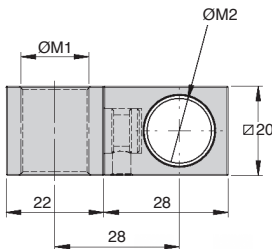

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRR8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	16,27 €
NRR8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	-	16,37 €
NRR8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	-	16,77 €
NRR10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	16,56 €
NRR10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	16,67 €
NRR12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	16,98 €

*Depending on availability - Dimensions in mm

Our other products




SCA_SS

Stainless steel flat cable clamp, Stainless steel



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel

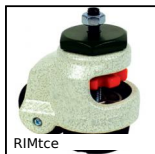

RIMtce

Locking castor, with central hole



KB_OP

Open precision linear bearing, Precision - steel



PRF4545_P

Strip Aluminium profile with extendable slot, 45 x 45 mm



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



EP7

Electronic digital position indicator, 5 numbers



MSP3815

Masterplate® glueable insert rectangular, rectangular with



RURp

Fixed castor with plate, Polyurethane -



DOMI120

Connecting kits, XZ linking kit



UTKpwrr

V shaped channel UtiliTrak®, V rail



DOMI50

Connecting kits, XY linking kit

Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp