

# Adjustable support clamp

Sta Stock

## NRR

## Easy to mount and adjust

- Support clamp with adjustable head

- Material:  
stainless steel

### Application

- Supporting sensors, connecting tubes when assembling small structures


### Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

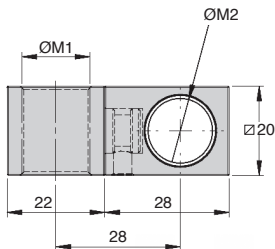

### DISCOUNTS

| Qty   | 1+   | 5+  | 10+  | 20+        |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | For rod ØA1 | Thread ØM1 | For rod ØA2 | Thread ØM2 | Used with sleeve  | Stock* | Price each 1 to 4 |
|-------------|-------------|------------|-------------|------------|-------------------|--------|-------------------|
| NRR8-8      | 8           | M12x1,5    | 8           | M12x1,5    | MBF8-12           | ✓      | 16,27 €           |
| NRR8-10     | 8           | M12x1,5    | 10          | M14x1,5    | MBF8-12/MBF10-14  | -      | 16,37 €           |
| NRR8-12     | 8           | M12x1,5    | 12          | M16x1,5    | MBF8-12/MBF12-16  | -      | 16,77 €           |
| NRR10-10    | 10          | M14x1,5    | 10          | M14x1,5    | MBF10-14          | ✓      | 16,56 €           |
| NRR10-12    | 10          | M14x1,5    | 12          | M16x1,5    | MBF10-14/MBF12-16 | -      | 16,67 €           |
| NRR12-12    | 12          | M16x1,5    | 12          | M16x1,5    | MBF12-16          | ✓      | 16,98 €           |

\*Depending on availability - Dimensions in mm

## Our other products



BH01

Single housed bearing, Bearing fitted with adhesive



RFV40

Stainless steel worm and wheel gearbox, up to 47 Nm



 
H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PRF\_GAL

Roller for aluminium profile, Fixing kit for roller concentric



M1

Worm and wheel set, Machined plastic (delrin)



GEC

Rubber latch clamp with strike plate, Lockable



G-ECO

Eco range Spur gear, Steel C45



EX

Optional shaft for E-type gear reducers, E Gearboxes single sided ou...



PGT

Sliding profile, Sliding panel support



PLM-C

Flat gripping magnet, Flat holding magnet



SHN

Hexagonal nut DIN934, A2 Stainless steel



BLHB50

Right angled gearbox, bored shafts, up to 30 Nm

## Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp