

Orthogonal support clamp

Sta Stock

NRV

Easy to mount and adjust

- 90° support clamp

- Material:
stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

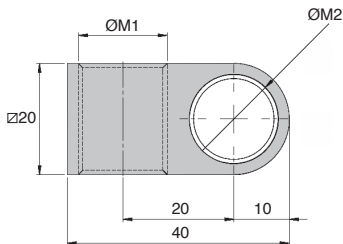

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRV8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	10,45 €
NRV8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	✓	10,56 €
NRV8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	✓	10,99 €
NRV10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	10,63 €
NRV10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	10,75 €
NRV12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	11,06 €

*Depending on availability - Dimensions in mm

Our other products



 
Q6

Deep groove ball bearing, Steel



BAG

Steel Clamping collar, Steel




PM3

Worm and wheel set, Bronze



PGM52-M4

 Pull handle, Brass



SLS

Bearing block for leadscrew, Fixed Drylin® bearing block



ACM_AZ

Mounting bracket for bonnet fastener, Hook



BRI

Panel holder, Panel holder



PRF_P

Anchor foot for 45x45 profile, Anchor foot



 
PSG1HC

Skive hobbed spur gears - precision



DIV

Locking bolt, With grip - Steel



SLVHlok

Vertical toggle clamp, Vertical toggle clamp /



CHB

Worm and wheel gear reducer, up to 73 Nm

Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp