

Orthogonal support clamp

Sta Stock

NRV

Easy to mount and adjust

- 90° support clamp

- Material:
stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

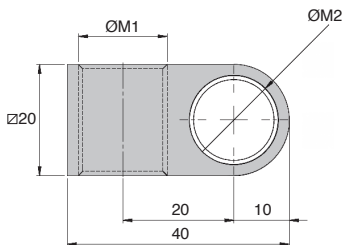

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRV8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	10,45 €
NRV8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	✓	10,56 €
NRV8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	✓	10,99 €
NRV10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	10,63 €
NRV10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	10,75 €
NRV12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	11,06 €

*Depending on availability - Dimensions in mm

Our other products



 
SSHBRA

Stainless steel bevel gear, 1,5:1 2:1 3:1




CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



BLHM20

 Right angled gearbox, double output shafts, up to 1.77 Nm



G0

Steel spur gear, Steel 20NCD2



DILC

Indexing plunger with cam, with cam



DOMI120

Accessories, Fixing kit



G2

Steel spur gear, Steel 20NCD2



F7-I

Multifunction display, With internal sensor



NKIA

Combined bearing with inner ring, Axial load in one direction



CLLCLLP

Clevis components, long version, Steel - long range



DOMI_MD

Domino rotary table, 55/1



HLU

Spoked handwheel without handle, Aluminium

Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp