

# Orthogonal support clamp

Sta Stock

## NRV

Easy to mount and adjust

- 90° support clamp

- Material:  
stainless steel

### Application


- Supporting sensors, connecting tubes when assembling small structures

### Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

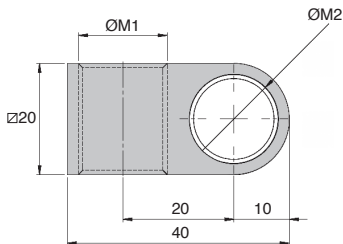


### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRV8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	10,45 €
NRV8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	✓	10,56 €
NRV8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	✓	10,99 €
NRV10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	10,63 €
NRV10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	10,75 €
NRV12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	11,06 €

\*Depending on availability - Dimensions in mm
 
## Our other products



MBrondelle

Stop washer, Stop washer MB



SNG

Stainless/Polymer pillow block bearing, Cast iron - Split pillow



SVT5

Screwjack with travelling screw, with translating screw



AC

Strike for toggle latch, 12mm



 
DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



PLA

Flat magnet, Flat magnet




M0

Worm and wheel set, Machined plastic (delrin)



CHA35

 Hinge for aluminium profile, Hinge




RPP

Connecting plate for RPP type timing belts,



SA\_SAKH

 Housing for linear bearing, Closed - light



EZY

Cylindrical stop, Steel



RTL450

Self-centering locking assembly, High torque

## Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp