

Orthogonal support clamp

Sta Stock

NRV

Easy to mount and adjust

- 90° support clamp

- Material:
stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

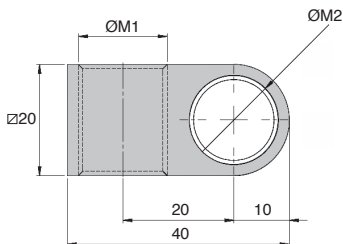

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRV8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	10,45 €
NRV8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	✓	10,56 €
NRV8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	✓	10,99 €
NRV10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	10,63 €
NRV10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	10,75 €
NRV12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	11,06 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



ZG4

Plastic spur gear,
Machined plastic
(delrin)



LVT

Miniature motorised
actuator 1A, 1 amper



RFK48B

Hypoid gearbox -
Stainless steel, up to
350 Nm



AC

Strike for toggle latch,
15mm



RAG-12-M8

Roller guide
accessory, Anchoring
system



SHN

Hexagonal nut
DIN934, A2 Stainless
steel



DKONSL

Silicone conical elasto
buffer, Male mounting



BABT

Hardened Stainless
steel ball pin,
Hardened stainless
steel



BPHF

Ball transfer unit push
fit, Heavy



RCX-6

Spherical tilt washer -
DIN6319, convex



M

Bellows cover,
Accessory:



R204

Die spring ISO10243,
Average

Complementary products



APBC

Circular rod, Round
rod



MBF

Threaded blocking
clamp, Threaded
locking clamp