

# Orthogonal support clamp

Sta Stock

## NRV

Easy to mount and adjust

- 90° support clamp

- Material:  
stainless steel

### Application


- Supporting sensors, connecting tubes when assembling small structures

### Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

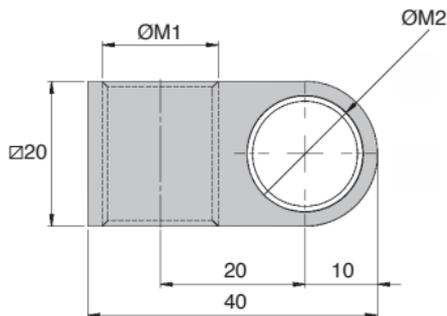

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA1	Thread ØM1	For rod ØA2	Thread ØM2	Used with sleeve	Stock*	Price each 1 to 4
NRV8-8	8	M12x1,5	8	M12x1,5	MBF8-12	✓	10,45 €
NRV8-10	8	M12x1,5	10	M14x1,5	MBF8-12/MBF10-14	✓	10,56 €
NRV8-12	8	M12x1,5	12	M16x1,5	MBF8-12/MBF12-16	✓	10,99 €
NRV10-10	10	M14x1,5	10	M14x1,5	MBF10-14	✓	10,63 €
NRV10-12	10	M14x1,5	12	M16x1,5	MBF10-14/MBF12-16	-	10,75 €
NRV12-12	12	M16x1,5	12	M16x1,5	MBF12-16	✓	11,06 €

\*Depending on availability - Dimensions in mm

## Our other products



CAP881  
Side flexing slim slat  
top chain stainless  
steel, Narrow range  
881



CLB\_T  
Die cast zinc clamping  
lever - male, Zamak



ACLEPP  
Right angled bracket  
for aluminium profile,  
2 holes



BZY\_SS  
Stainless steel  
cylindrical elasto  
mount, Stainless steel



GMK17\_BR  
Clamp for guiding  
profile, Rounded only  
- single



PRF\_BV  
Screw block, Panel  
addition and fastening



Q6  
Deep groove ball  
bearing, Steel



HCA  
Magnetic screw with  
socket, Steel



MEB  
Moulded plastic bevel  
gear (nylon), 1:1



T10courroie  
T type timing belt,  
T10 Steel cored



SUP  
Self-centering  
clamping hub steel,



GBS  
Nut for ballscrew,  
Flanged ballscrew nut

## Complementary products



APBC  
Circular rod, Round  
rod



MBF  
Threaded blocking  
clamp, Threaded  
locking clamp