



Articulated clamp


For rod or tube

NSA

- For clamping cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob for quick tightening

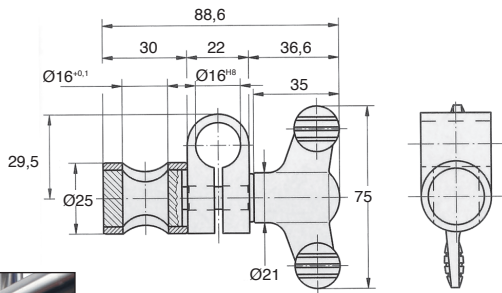

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	For shaft	Weight (kg)	Stock*	Price each 1 to 4
NSA-16	Ø16	0,150	✓	60,88 €

*Depending on availability - Dimensions in mm

Our other products



PRF_GAL
Roller for aluminium profile, Flat roller



YG3
HEAVY DUTY spur gear, Steel 35NCD6



CFS
Miniature cam follower, Miniature



AK
Bellows coupling Gerwah®, from 36 to 800Nm



PRF4545
Standard stainless steel profile, 45 x 45 mm



SSHBRA
Stainless steel bevel gear, 1,5:1 2:1 3:1



LACT_SS
Adjustable Stainless steel cam lever, Male



ADL_F
Female eye bolt conforms to DIN582, Steel



B_ECO
Eco. range steel bevel gear, 1:1



SNG
Stainless/Polymer pillow block bearing,



PRS80
Stainless steel articulated foot Ø80,



PITA
Locking bolt, with T handle

Complementary products



NSR
Adjustable clamp, Adjustable



NJM
Multiple junction clamp, Multiple