



Articulated clamp


For rod or tube

NSA

- For clamping cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob for quick tightening

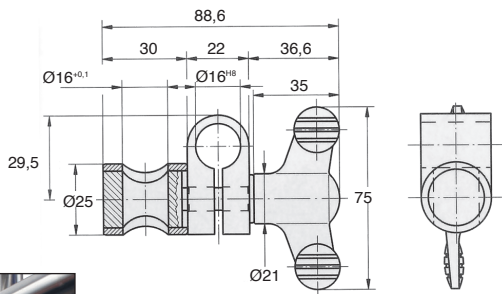

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	For shaft	Weight (kg)	Stock*	Price each 1 to 4
NSA-16	Ø16	0,150	✓	60,88 €

*Depending on availability - Dimensions in mm

Our other products



CHAE6555
Decorative screwed hinge, Aluminium



PSG05
Spur gear - precision range, Pre-hardened Steel 35NCD6



NKIB
Combined bearing with inner ring, Axial load in both directions



WINGbrEcrou
Manually tightened wing nut DIN315, Brass DIN 315



WJUM10
Drylin® W bearing block, Slide



SRP
Slotted spring pin ISO8752, Split ISO 8752



 
CHAFR-MINI
Miniature friction hinge, Friction



VDSCB
Sliding lock adjustment system, Blocking wedge for sliding lock for ...



ZBconique
Machined plastic bevel gear, 1:1



PO
Pull handle - Multi-sector, Smooth hole



ZBconique
Machined plastic bevel gear, 1:1



BPH
Ball transfer unit plain fit, High

Complementary products



NSR
Adjustable clamp, Adjustable



NJM
Multiple junction clamp, Multiple



NPTR
Adjustable cross clamp, Adjustable



NPTR10
Adjustable cross clamp, Adjustable