



Standard linear bearing housing **Alu** **Stock**

NSB For KB, TK and RJUM bearings

- Housing for closed bearing
- Bearing not supplied
- Material : Aluminium

Options

- Compatible with KB, TK and RJUM ranges

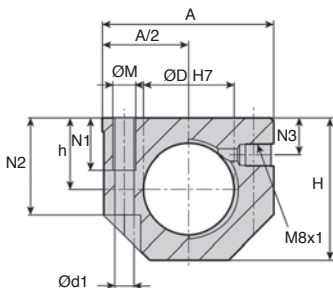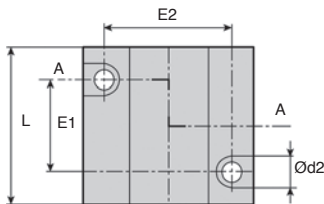

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft		H	h +0.01/- 0.02	A	L +0.3	N1	N2	N3	E1 +0.2	E2 +0.2	Ød1	Ød2	ØM	Stock*	Price each 1 to 4
	Ød	ØD														
NSB12	12	22	35	18	43	39	13	25	10	23	32	4,2	8	M5	✓	38,55 €
NSB16	16	26	42	22	53	43	13	30	12	26	40	5,2	10	M6	✓	43,77 €
NSB20	20	32	50	25	60	54	18	34	13	32	45	6,8	11	M8	✓	47,94 €
NSB25	25	40	60	30	78	67	22	40	15	40	60	8,6	15	M10	✓	60,45 €
NSB30	30	47	70	35	87	79	22	48	16	45	68	8,6	15	M10	✓	69,87 €

*Depending on availability - Dimensions in mm

Our other products



MAC

Carabiner DIN5299
steel, Steel




BABFCFO

Ball pin socket,
Mounting collar with a
oval flange



DOMI120

Accessories, Clamping
lever

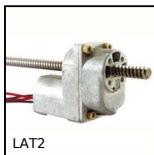

LAT2

2A motorised linear
actuator, 2 amperes



CHM50

Worm and wheel gear
reducer, up to 107
Nm



SEH

Horizontal stirrup
toggle clamp,
Horizontal stirrup
clamp - steel



BABT

Hardened Stainless
steel ball pin,
Hardened stainless
steel



DCG

Suction cup, 2.5
bellows, natural
rubber



RLXAC8

Free roller, Steel



VDSQ

Sliding lock
adjustment system,
Sliding lock for square
profile



DOMI50

Accessories, Plate



BSM_LOK

Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...

Complementary products



KB_UU

Closed linear
precision bearing,
Precision - steel




TK

Topball self-aligning
linear bearing, Topball
self-aligning



ZB

Shaft for linear
guides, Hardened
ground stainless steel

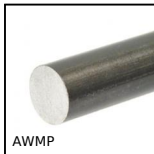

AWMP

Aluminium shaft for
linear guide,
Aluminium