



Standard linear bearing housing **Alu** **Stock**

NSB For KB, TK and RJUM bearings

- Housing for closed bearing
- Bearing not supplied
- Material : Aluminium

Options

- Compatible with KB, TK and RJUM ranges

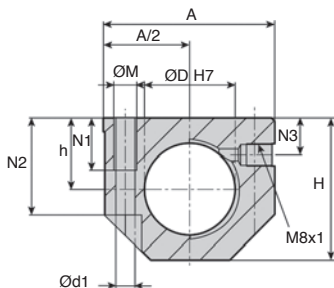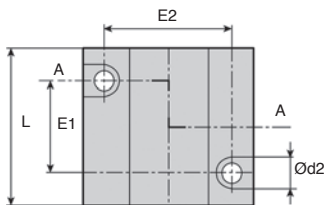

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 5+ | 10+ | 25+ |
| Disc. | List | -6% | -12% | On request |

| Part number | For shaft | | H | h | | L | | | | E1 | E2 | Ød1 | Ød2 | ØM | Stock* | Price each 1 to 4 |
|-------------|-----------|----|----|-------------|----|------|----|----|----|----|----|-----|-----|-----|--------|----------------------|
| | Ød | ØD | | +0.01/-0.02 | A | +0.3 | N1 | N2 | N3 | | | | | | | |
| NSB12 | 12 | 22 | 35 | 18 | 43 | 39 | 13 | 25 | 10 | 23 | 32 | 4,2 | 8 | M5 | ✓ | 38,55 € |
| NSB16 | 16 | 26 | 42 | 22 | 53 | 43 | 13 | 30 | 12 | 26 | 40 | 5,2 | 10 | M6 | ✓ | 43,77 € |
| NSB20 | 20 | 32 | 50 | 25 | 60 | 54 | 18 | 34 | 13 | 32 | 45 | 6,8 | 11 | M8 | ✓ | 47,94 € |
| NSB25 | 25 | 40 | 60 | 30 | 78 | 67 | 22 | 40 | 15 | 40 | 60 | 8,6 | 15 | M10 | ✓ | 60,45 € |
| NSB30 | 30 | 47 | 70 | 35 | 87 | 79 | 22 | 48 | 16 | 45 | 68 | 8,6 | 15 | M10 | ✓ | 69,87 € |

*Depending on availability - Dimensions in mm


Our other products



GP75
Spring loaded toggle latch, Standard (GP75)



OP3
Mechanical digital position indicator, 4 numbers

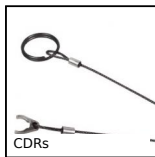

CDRs
Retaining cable for ball pin, Retaining cable



SH1
Parallel axis helical gear, Steel 20NCD2



PSG125
Spur gear - precision range, Pre-hardened Steel 35NCD6



WSS
Symmetrical S shaped hook, Steel



GE32
Sprung toggle latch with connecting link, Standard



HCV
V- rail guidance Simple Select® system, on rail



H3
Crossed helical gear crossed axis at 90°, Machined plastic



BMM
Knurled knob - male, Knurled



CHA1056_U4
Screw-in hinge, Section 40X40



DOG258
Motor-gearbox 12V and 24V DC, from 12 to 15 Nm

Complementary products



 
KB_UU
Closed linear precision bearing, Precision - steel



TK
Topball self-aligning linear bearing, Topball self-aligning



ZB
Shaft for linear guides, Hardened ground stainless steel



AWMP
Aluminium shaft for linear guide, Aluminium