

Straight support clamp

Sta Stock

NSD

Easy to mount and adjust

- Support clamp for use with 8mm T slots

- Material:
stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with **MBF** sleeves and **APBC** rods



Suitable for food industry use

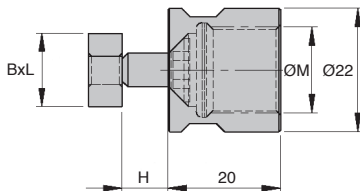

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	B	L	H	Used with sleeve	Stock*	Price each 1 to 4
NSD8-12	8	M12x1,5	8	13	0-10	MBF8-12	-	7,26 €
NSD10-14	10	M14x1,5	8	13	0-10	MBF10-14	-	7,46 €
NSD12-16	12	M16x1,5	8	13	0-10	MBF12-16	✓	7,64 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PR530

Stainless steel articulated foot Ø30, Ø 30



GAL48_OMNI

Omni-directional roller, Omni-directional



NT61

Spur gear coaxial gearbox, from 5 to 14 Nm - In-line



MPS

Hexagonal spacer, Stainless steel 303



V3RA_PTR

3-spoked handwheel with foldable handle, Polyamide




M0

Worm and wheel set, Hardened steel



CHMR110

Worm and wheel gear reducer, up to 980 Nm

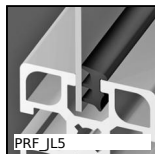

PRF_JL5

Lip seal for panel, Door seal - Ø 5mm



CHASb89

Hinge without pin, Plastic hinge



PLB

Cylindrical spacer, Brass



MACss

Stainless steel carabiner, Stainless steel



TCL-PD

T-Clip - Aluminium profile attachment, Cable support

Complementary products



APBC

Circular rod, Round rod



MBF

Threaded blocking clamp, Threaded locking clamp