

# Housing for open linear bearing **Alu** **Stock**

## NSO For KB-OP and TK-OP bearings



- Open housing for open bearing
- Bearing not supplied
- Material:  
Aluminium
- Circlips used for assembly

### Options

- Compatible with KB-OP and TK-OP ranges

### Advantages

- Use with long supported shafts to avoid flexing.

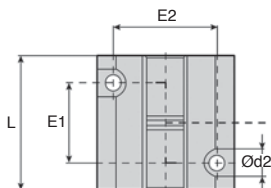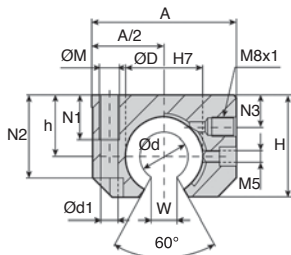

### DISCOUNTS

 
Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft Ød	ØD	H	h	A	L	E1	E2	N1
NSO12	12	22	28	18	43	39	23	32	11
NSO16	16	26	35	22	53	43	26	40	13
NSO20	20	32	42	25	60	54	32	45	18
NSO25	25	40	51	30	78	67	40	60	22
NSO30	30	47	60	35	87	79	45	68	22
NSO40	40	62	77	45	108	91	58	86	26

Part number	N2	N3	Ød1	Ød2	ØM	W	Masse (g)	Stock*	Price each 1 to 4
NSO12	23,5	8	4,2	8	M5	7,0	110	✓	58,38 €
NSO16	30,0	12	5,2	10	M6	9,4	170	✓	60,45 €
NSO20	34,0	13	6,8	11	M8	10,2	300	✓	66,72 €
NSO25	40,0	15	8,6	15	M10	12,5	570	✓	80,26 €
NSO30	48,0	16	8,6	15	M10	13,9	860	✓	94,89 €
NSO40	60,0	20	10,3	18	M12	18,0	1600	✓	159,57 €


\*Depending on availability - Dimensions in mm

## Our other products



RPP5

 RPP heavy duty timing belt, RPP5



SCA

Flat cable clamp, Steel



E40

Right angle helical reducers, from 2.30 to 20 Nm



GLT3-46A

Telescopic drawer with damper,



BOX-CS

Hose clamp, Box set of steel hose clamps



RJUM05

Drylin R® linear bearing housing, Closed - Long



HTD8M\_20

HTD Heavy duty timing pulley, HTD8 Cast



CHN\_CHNSS

Straight long link stainless steel chain, Stainless steel



PGT

Sliding profile, Sliding panel support



BSCf

Knurled torque knobs - female, Knurled



TM\_CTM\_CTF

Suction cup threaded insert, Insert for



STRIP


Sealing brush strip, 3m length

## Complementary products



 KB\_OP

Open precision linear bearing, Precision - steel



FTSN

Supported shaft for linear guide, Steel shaft / Aluminium support



S20

Short housing for open linear bearing, Opened - slim