

# Housing for open linear bearing **Alu** **Stock**

## NSO For KB-OP and TK-OP bearings



- Open housing for open bearing
- Bearing not supplied
- Material:  
Aluminium
- Circlips used for assembly

### Options

- Compatible with KB-OP and TK-OP ranges

### Advantages

- Use with long supported shafts to avoid flexing.

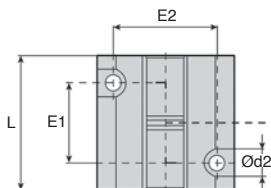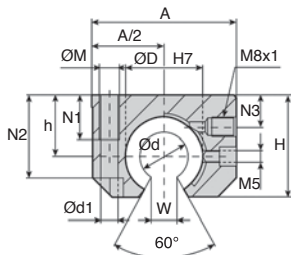

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft Ød	ØD	H	h	A	L	E1	E2	N1
NSO12	12	22	28	18	43	39	23	32	11
NSO16	16	26	35	22	53	43	26	40	13
NSO20	20	32	42	25	60	54	32	45	18
NSO25	25	40	51	30	78	67	40	60	22
NSO30	30	47	60	35	87	79	45	68	22
NSO40	40	62	77	45	108	91	58	86	26

Part number	N2	N3	Ød1	Ød2	ØM	W	Masse (g)	Stock*	Price each 1 to 4
NSO12	23,5	8	4,2	8	M5	7,0	110	✓	58,38 €
NSO16	30,0	12	5,2	10	M6	9,4	170	✓	60,45 €
NSO20	34,0	13	6,8	11	M8	10,2	300	✓	66,72 €
NSO25	40,0	15	8,6	15	M10	12,5	570	✓	80,26 €
NSO30	48,0	16	8,6	15	M10	13,9	860	✓	94,89 €
NSO40	60,0	20	10,3	18	M12	18,0	1600	✓	159,57 €

\*Depending on availability - Dimensions in mm

## Our other products



 
ADL\_M

Male eye bolt conforms to DIN580, Stainless steel



J64

Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SSHBRA

Stainless steel bevel gear, 1,5:1 2:1 3:1



BAC105

Storage bin, 8mm



PLC\_PLT

Magnetic stud with threaded hole, With threaded hole



SH1

Parallel axis helical gear, Steel 20NCD2



SUA4\_L

Chain link, Steel



ETGamme

Extension springs DIN2097, DIN 2097



AT5-10ECO

AT type timing pulley, Economy range - AT5 aluminium



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free



S20


Short housing for open linear bearing, Opened - slim

## Complementary products



KB\_OP

Open precision linear bearing, Precision - steel

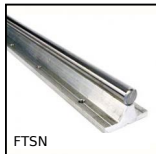

FTSN

Supported shaft for linear guide, Steel shaft / Aluminium support



S20

Short housing for open linear bearing, Opened - slim