

# Right angled support clamp

Sta Stock

## NSP

## Easy to mount and adjust



- Support clamp for use with 8 mm T slots
- Material:  
stainless steel

### Application

- Supporting sensors, connecting tubes when assembling small structures

### Accessories

- To be used with **MBF** sleeves and **APBC** rods

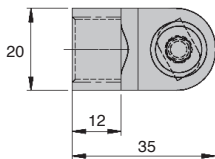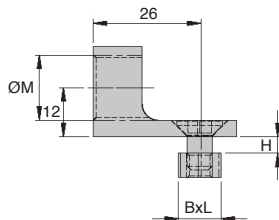

Suitable for food industry use

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	H	B	L	Used with sleeve	Stock*	Price each 1 to 4
NSP8-12	8	M12x1,5	0-10	8	13	MBF8-12	✓	16,98 €
NSP10-14	10	M14x1,5	0-10	8	13	MBF10-14	✓	17,20 €
NSP12-16	12	M16x1,5	0-10	8	13	MBF12-16	✓	17,49 €

\*Depending on availability - Dimensions in mm

## Our other products



ZA

Shaft for linear guides, Hardened ground steel



RHTplss

High Temperature Castor, up to 200kg



SLB

Indexing plunger, steel class 5.8



NANO

Speed controller 3A, 3 A



G-ECO2

Eco range Spur gear, Steel C45



ACL-PR

Joining plate for aluminium profile, Right angled connection



KB\_WW

Closed linear precision bearing, Economy range



LVTMFC

Device for controlling limit switches, For mini-actuator LVT



ZB

Shaft for linear guides, Hardened ground stainless steel



T5P\_T10P

Connecting plate for T type timing belts, T10



RBGpl

Fixed castor with plate, Steel - grey rubber



NCT

Square tube connector, Fixed angle

## Complementary products



MBF

Threaded blocking clamp, Threaded locking clamp



APBC

Circular rod, Round rod