

# Right angled support clamp

Sta Stock

## NSP

## Easy to mount and adjust



- Support clamp for use with 8 mm T slots
- Material:  
stainless steel

### Application

- Supporting sensors, connecting tubes when assembling small structures

### Accessories

- To be used with **MBF** sleeves and **APBC** rods

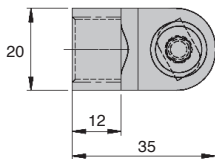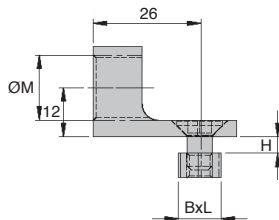

Suitable for food industry use

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	H	B	L	Used with sleeve	Stock*	Price each 1 to 4
NSP8-12	8	M12x1,5	0-10	8	13	MBF8-12	✓	16,98 €
NSP10-14	10	M14x1,5	0-10	8	13	MBF10-14	✓	17,20 €
NSP12-16	12	M16x1,5	0-10	8	13	MBF12-16	✓	17,49 €

\*Depending on availability - Dimensions in mm

## Our other products



AC144

Strike for toggle latch,  
22mm



PW\_PWG25

Wheel - precision  
range, Bronze




PMC150\_M16

Anti-vibration  
machine mount,  
Square base plate



PCS62

 Chain sprocket - steel,  
15.875 (DIN 10B-1)



PX\_PO

Carrying handle, back-  
plated



PDM\_PDVB

Detectable plastic  
palm grip, blue  
thermoplastic



IBJ

180° ball and socket  
joints, Steel



DCA

Suction cup, 1.5  
bellows, silicon



DOG316

Motor-gearbox 12V  
and 24V DC, from 1.5



GPB

Threaded spherical  
knob, With brass



PCS75K

Chain sprocket with  
hardened teeth,



T5P\_T10P

Connecting plate for T  
type timing belts, T10

## Complementary products



MBF

Threaded blocking  
clamp, Threaded  
locking clamp



APBC

Circular rod, Round  
rod