

Right angled support clamp

Sta Stock

NSP

Easy to mount and adjust



- Support clamp for use with 8 mm T slots
- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with **MBF** sleeves and **APBC** rods

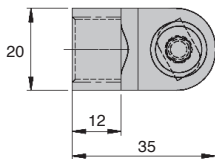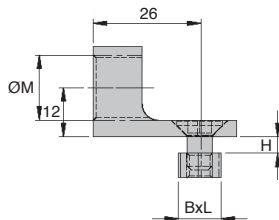

Suitable for food industry use

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	H	B	L	Used with sleeve	Stock*	Price each 1 to 4
NSP8-12	8	M12x1,5	0-10	8	13	MBF8-12	✓	16,98 €
NSP10-14	10	M14x1,5	0-10	8	13	MBF10-14	✓	17,20 €
NSP12-16	12	M16x1,5	0-10	8	13	MBF12-16	✓	17,49 €

*Depending on availability - Dimensions in mm

Our other products



DB

Steel bevel gear, 2:1



RAG-12-M8

Roller guide accessory, Anchoring system



ADL_F

Female eye bolt conforms to DIN582, Steel



LRX

Linear roller slide, Rail - from 9410 N to 101000 N



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



NPTF30

Fixed tube carrier, Fixed Ø14 to Ø20



GE_ET_2RS

Spherical bushing, Hard chromium / Teflon contact with seals



 
CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



ACLBT5

Closing system for aluminium profile, 90° bracket for spherical



HK

Manual locking clamp, Manual locking clamp LRX



P15

Worm and wheel gear reducer, up to 3,75 Nm

Complementary products



MBF

Threaded blocking clamp, Threaded locking clamp



APBC

Circular rod, Round rod