

# Adjustable clamp



## NSR

## For rod or tube

- Holds cylindrical sections (rods, tubes...)


- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: steel, resistance class 5.8

Other parts: high-resistance anodised aluminium

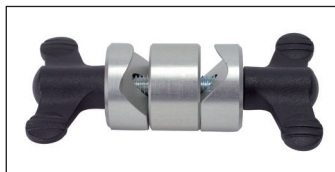


### Advantages

- Each side adjusts individually, no bearing

- Simple construction using wing nuts

- Tightens quickly

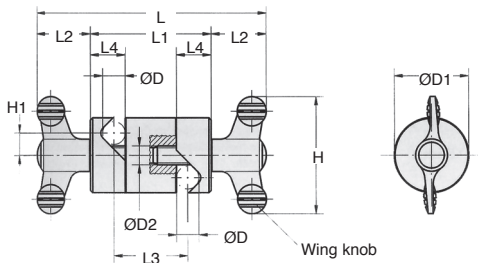

Typical application

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	Weight (kg)	Stock*	Price each 1 to 4
NSR-8	8	28	M8	90	42	24	24	13	50	8,5	0,086	-	37,80 €
NSR-10	10	32	M8	100	52	24	32	15	50	9,5	0,124	✓	39,57 €
NSR-12	12	36	M8	104	56	24	34	17	50	10,5	0,157	✓	45,30 €
NSR-16	16	45	M10	142	72	35	44	22	75	13,5	0,345	✓	57,68 €
NSR-20	20	74	M10	172	102	35	62	30	75	22,0	1,110	✓	86,35 €

\*Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



BLM

Spring loaded plunger with ball tip, Plastic body



LRR-53

Spring loaded latch, Spring return latch - stainless steel



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



TUBE25\_25

Square Tube, Aluminium or Stainless steel



 
D-PAR\_SS

Stainless steel progressive stop, stainless steel



CMAss

Eye bolt stainless steel, Stainless steel



RDE-W

Sealing washer Hygienic Usit®, Stainless steel - White EPDM



M0

Worm and wheel set, Non hardened steel



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



COA-COG

Surface mounting plate, Surface mounting plate for



CLA

Clamping lever Hygienic Usit® - female, Stainless steel

## Complementary products



NSA

Adjustable clamp, Articulated



NJM

Multiple junction clamp, Multiple