

Adjustable clamp



NSR

For rod or tube

- Holds cylindrical sections (rods, tubes...)


- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: steel, resistance class 5.8

Other parts: high-resistance anodised aluminium

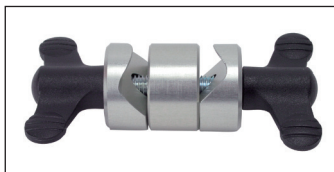


Advantages

- Each side adjusts individually, no bearing

- Simple construction using wing nuts

- Tightens quickly

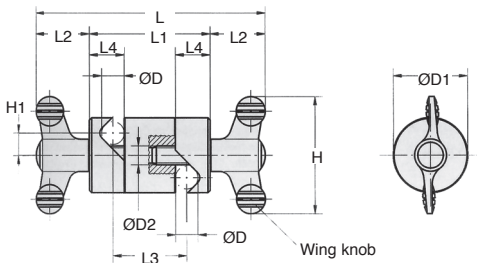

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	Weight (kg)	Stock*	Price each 1 to 4
NSR-8	8	28	M8	90	42	24	24	13	50	8,5	0,086	-	37,80 €
NSR-10	10	32	M8	100	52	24	32	15	50	9,5	0,124	✓	39,57 €
NSR-12	12	36	M8	104	56	24	34	17	50	10,5	0,157	✓	45,30 €
NSR-16	16	45	M10	142	72	35	44	22	75	13,5	0,345	✓	57,68 €
NSR-20	20	74	M10	172	102	35	62	30	75	22,0	1,110	✓	86,35 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BPF1ss
Pressed stainless steel flange bearing,
Stainless steel



PRES2HR
Manual workbench press, Force up to
200kg




VRC2
Retaining clamp, dual
sided, Dual sided



GMK17_R
Round guide, Round
guide for conical
profile



 GARBAB
Lock pin for clamping,
Ball lock pin



SHTP
Drylin® Linear table,
Economy range



NCT
Square tube
connector, Fixed
angle



 
SBF
Sealed flange bearing
unit for Food Industry,
cover



T5M_T10M
T type timing belt per
metre, T10 Steel
cored polyurethane



FUSS
Bearing locknut, Self
locking locknut -
stainless steel lock



PRF-GUM
Aluminium profile
anodising polisher,
Polishing block



BUH77
Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm

Complementary products



NSA
Adjustable clamp,
Articulated



NJM
Multiple junction
clamp, Multiple