


Adjustable clamp



NSR


For rod or tube

- Holds cylindrical sections (rods, tubes...)
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Screw: steel, resistance class 5.8
Other parts: high-resistance anodised aluminium

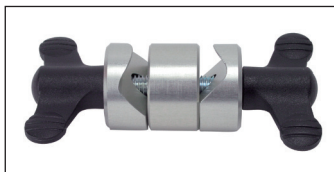

Advantages

- Each side adjusts individually, no bearing
- Simple construction using wing nuts
- Tightens quickly

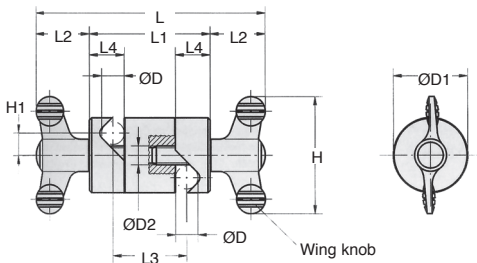

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	Weight (kg)	Stock*	Price each 1 to 4
NSR-8	8	28	M8	90	42	24	24	13	50	8,5	0,086	-	37,80 €
NSR-10	10	32	M8	100	52	24	32	15	50	9,5	0,124	✓	39,57 €
NSR-12	12	36	M8	104	56	24	34	17	50	10,5	0,157	✓	45,30 €
NSR-16	16	45	M10	142	72	35	44	22	75	13,5	0,345	✓	57,68 €
NSR-20	20	74	M10	172	102	35	62	30	75	22,0	1,110	✓	86,35 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



P40
Worm and wheel gear reducer, up to 18 Nm



T5M T10M
T type timing belt per metre, T5 Steel cored polyurethane



PO
Pull handle - Multi-sector, Tapped recessed insert



 
VPR
Wing screw Hygienic Usit®, Stainless steel



ZBconique
Machined plastic bevel gear, 1:1




BOXbeta
Box of assorted hitch pins, Boxed set - hitch



TCXR
Automatic chain tensioner, With steel sprocket



 ADL_M
Male eye bolt conforms to DIN580, Steel



G1
Steel spur gear, Steel 20NCD2



CHML63
Worm and wheel gear reducer, up to 138 Nm - Integrated



CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective



VT
Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm

Complementary products



NSA
Adjustable clamp, Articulated



NJM
Multiple junction clamp, Multiple