

Universal 90° support clamp

Sta Stock

NSU

Easy to mount and adjust

- Support clamp with adjustable head
- Head can be adjusted by loosening and then tightening countersunk screw before assembly
- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures



Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

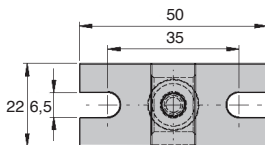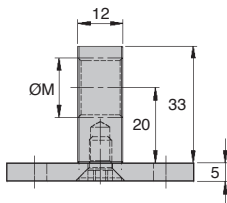

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	Used with sleeve	Stock*	Price each 1 to 4
NSU8-12	8	M12x1,5	MBF8-12	✓	13,27 €
NSU10-14	10	M14x1,5	MBF10-14	✓	13,46 €
NSU12-16	12	M16x1,5	MBF12-16	✓	13,65 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

 
www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CLLCLLP
Clevis components,
long version, Steel -
long version



M0
Wormwheel, Bronze



HTD5M-BAR
HTD type tooth bar
stock, HTD5



AK
Bellows coupling
Gerwah®, from 36 to
800Nm



SH0
Parallel axis helical
gear, Steel 20NCD2



KON
Conical elasto buffer,
Stainless steel



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



AC
Strike for toggle latch,
20mm




CTZY
Diabolo shaped elasto
mount, Steel



BEAB
Knob star grip
antibacterial, Star,
anti-bacterial



PRF_T
Corner reinforcement,
Corner reinforcement

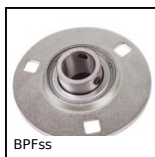

BPFss
Pressed stainless
steel flange bearing,
Stainless steel

Complementary products



MBF
Threaded blocking
clamp, Threaded
locking clamp



APBC
Circular rod, Round
rod