

Universal 90° support clamp

Sta Stock

NSU

Easy to mount and adjust

- **Support clamp with adjustable head**
- Head can be adjusted by loosening and then tightening countersunk screw before assembly
- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures



Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless
steel



Suitable for food
industry use

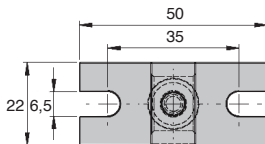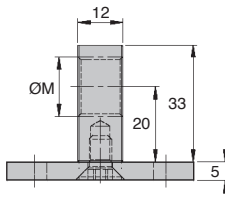

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	Used with sleeve	Stock*	Price each 1 to 4
NSU8-12	8	M12x1,5	MBF8-12	✓	13,27 €
NSU10-14	10	M14x1,5	MBF10-14	✓	13,46 €
NSU12-16	12	M16x1,5	MBF12-16	✓	13,65 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RCC_RCX
Spherical tilt washer -
DIN6319, concave



BOX-TOR-MAX
Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 82.14 x
3.53



CSS
Spherical bushing,
Steel / self lubricating
steel



BL8
Right angled gearbox,
from 0.20 to 2 Nm



PLM-20SC
Cylindrical magnet,
Cylindrical magnet



BABS
630 Stainless steel
compact ball pin,
Hardened stainless
steel



SBF
Sealed flange bearing
unit for Food Industry,
cover



VEL
Self-gripping cable
strip, electric and
pneumatic cables



DPAR_DKON
Conical elasto buffer,
Steel



H0
Crossed helical gear
crossed axis at 90°



RIMple
Locking castor, with
mounting plate



M1
Worm and wheel set,
Hardened steel

Complementary products



MBF
Threaded blocking
clamp, Threaded
locking clamp



APBC
Circular rod, Round
rod