

# Universal 90° support clamp

Sta Stock

## NSU

## Easy to mount and adjust

- Support clamp with adjustable head
- Head can be adjusted by loosening and then tightening countersunk screw before assembly
- Material:  
stainless steel

### Application

- Supporting sensors, connecting tubes when assembling small structures



### Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

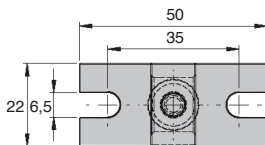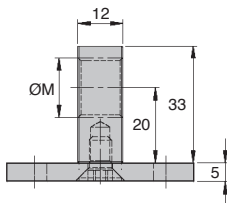

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	Used with sleeve	Stock*	Price each 1 to 4
NSU8-12	8	M12x1,5	MBF8-12	✓	13,27 €
NSU10-14	10	M14x1,5	MBF10-14	✓	13,46 €
NSU12-16	12	M16x1,5	MBF12-16	✓	13,65 €

\*Depending on availability - Dimensions in mm

## Our other products



RPCplss

Fixed castor with plate, Stainless steel - Polyamide



PRF\_JL2

Lip seal for panel, Door seal - Ø 2mm



PTCR

Adjustable furniture foot, square tube



LOQ

Manual lock, Manual latch



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



PSG125S

Spur gear - precision range 316



CHAE4080PA

Symmetrical decorative screwed hinge, Polyamide



PLM-16A

Magnetic stud with threaded hole, With threaded hole



CLSCLP

Clevis components, short version, Steel - short range



RMSA

Adjustable shock-absorber, Adjustable



PRF\_ECL

Nut for aluminium profile, Stainless steel square nut with tab



CHM50-MOT

Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW

## Complementary products



MBF

Threaded blocking clamp, Threaded locking clamp



APBC

Circular rod, Round rod