

# Universal 90° support clamp

Sta Stock

## NSU

## Easy to mount and adjust

- Support clamp with adjustable head
- Head can be adjusted by loosening and then tightening countersunk screw before assembly
- Material:  
stainless steel

### Application

- Supporting sensors, connecting tubes when assembling small structures



### Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

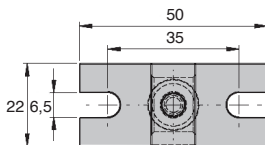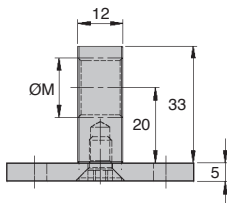

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	Used with sleeve	Stock*	Price each 1 to 4
NSU8-12	8	M12x1,5	MBF8-12	✓	13,27 €
NSU10-14	10	M14x1,5	MBF10-14	✓	13,46 €
NSU12-16	12	M16x1,5	MBF12-16	✓	13,65 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



MDB\_MTB  
Moulded plastic bevel gear (nylon), 2:1



PAS  
Pull handle, Reinforced PA thermoplastic



RFVcap  
Stainless steel protective cover, Closed protective cover



NT63  
Spur gear coaxial gearbox, from 8 to 20 Nm - Inline



MRA\_SS  
Stainless steel Quick link, Stainless steel



ACL-PLAngle  
Joining plate for aluminium profile, Angle connection



DPAR\_DKON  
Conical elasto buffer, Steel



ACL-PR  
Joining plate for aluminium profile, Right angled connection




HTD8M\_20  
HTD Heavy duty timing pulley, HTD8 Steel



SH1  
Parallel axis helical gear, Steel 20NCD2



RTL450  
Self-centering locking assembly, High torque

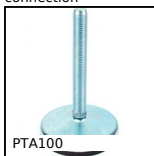

PTA100  
Articulated levelling foot, pressed base Ø100, Ø100

## Complementary products



MBF  
Threaded blocking clamp, Threaded locking clamp



APBC  
Circular rod, Round rod