

Universal 90° support clamp

Sta Stock

NSU

Easy to mount and adjust

- **Support clamp with adjustable head**
- Head can be adjusted by loosening and then tightening countersunk screw before assembly
- Material:
stainless steel

Application

- Supporting sensors, connecting tubes when assembling small structures



Accessories

- To be used with **MBF** sleeves and **APBC** rods

stainless steel



Suitable for food industry use

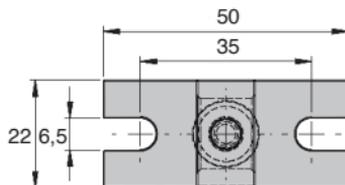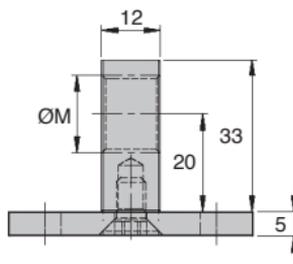

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Thread ØM	Used with sleeve	Stock*	Price each 1 to 4
NSU8-12	8	M12x1,5	MBF8-12	✓	13,27 €
NSU10-14	10	M14x1,5	MBF10-14	✓	13,46 €
NSU12-16	12	M16x1,5	MBF12-16	✓	13,65 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHT

Asynchronous AC Motor, 0.55 to 1.1kW



HG5-ECO

Eco range Spur gear, Steel C45



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



SLB

Indexing plunger, stainless steel



V3RA_PT

3-spoked handwheel with handle, Polyamide



TBV

Manual lifting tables, 12kg



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



BTC

End cap for square tube, Standard



EAR

Bearing locknut, Self locking locknut - nylon lock washer




KON

Conical elasto buffer, Stainless steel



Q6

Deep groove ball bearing, Steel

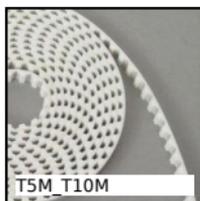

T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane

Complementary products



MBF

Threaded blocking clamp, Threaded locking clamp



APBC

Circular rod, Round rod