


- Does not damage shafts
- Self-locking
- Nylon tip adapts to shaft and increases grip
- Materials :  
Stainless steel  
Nylon head (colour can vary depending on stock availability)

Nylon tip

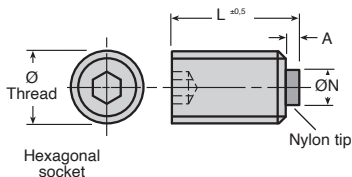

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-15%	On request

Part number	Ø Thread	Pitch	L	ØN	A	Stock*	Price each 1 to 5
NTM2-4	M2	0,4	4,0	0,8	0,8	✓	15,07 €
NTM2-5	M2	0,4	5,0	0,8	0,8	✓	13,58 €
NTM2-6	M2	0,4	6,0	0,8	0,8	✓	10,07 €
NTM2-7	M2	0,4	7,0	0,8	0,8	✓	22,60 €
NTM3-4	M3	0,5	4,0	1,6	0,8	✓	7,65 €
NTM3-5	M3	0,5	5,0	1,6	0,8	✓	5,73 €
NTM3-6	M3	0,5	6,0	1,6	0,8	✓	8,97 €
NTM4-5	M4	0,7	5,0	2,4	1,2	✓	7,14 €
NTM4-7	M4	0,7	7,0	2,4	1,2	✓	5,40 €
NTM4-11	M4	0,7	11,0	2,4	1,2	✓	6,74 €
NTM4-15	M4	0,7	15,0	2,4	1,2	✓	25,26 €
NTM5-7	M5	0,8	7,0	2,4	1,2	✓	17,12 €
NTM5-11	M5	0,8	11,0	2,4	1,2	✓	5,40 €
NTM5-15	M5	0,8	15,0	2,4	1,2	✓	8,79 €
NTM5-21	M5	0,8	21,0	2,4	1,2	✓	8,40 €
NTM6-7.5	M6	1,0	7,5	3,2	1,6	✓	6,74 €
NTM6-11.5	M6	1,0	11,5	3,2	1,6	✓	6,93 €
NTM6-17.5	M6	1,0	17,5	3,2	1,6	✓	12,19 €
NTM6-26.5	M6	1,0	26,5	3,2	1,6	✓	13,93 €
NTM10-14.5	M10	1,5	14,5	4,8	2,4	-	11,11 €
NTM10-22.5	M10	1,5	22,5	4,8	2,4	-	25,46 €

\*Depending on availability - Dimensions in mm

## Our other products



GE

Toggle latches,  
Miniature




BOX-TOR-D

Box set of Nitrile O-  
rings in nitrile, 18.00 x  
2.00mm to 50.00 x  
5.00



PLM-16A

Magnetic stud with  
threaded hole, With  
threaded hole

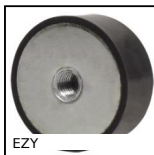


EZY

Cylindrical stop, Steel



PRF\_SDD\_1820

 Support for Ø18 or  
Ø20mm Prox  
detector, Ø18 and  
Ø20



PTBss

Threaded eye hook  
stainless steel,  
Stainless steel



 
APBC

Circular rod, Round  
rod



RCC\_RCX

Spherical tilt washer -  
DIN6319, convex



CTss

Universal joint,  
telescopic, Inox, Light  
duty



TAC

Rigging screw  
(hook/eye), Steel



PO

Pull handle - Multi-  
sector, Tapped  
recessed insert



BTESS

Universal stainless  
steel arm for  
tensioner, For use in  
hostile envi...

## Complementary products



NTMdl

Set screw delrin tip,  
Delrin-point



NTMbr

Set screw brass tip,  
Brass-point