


- Does not damage shafts
- Self-locking
- Nylon tip adapts to shaft and increases grip
- Materials :
Stainless steel
Nylon head (colour can vary depending on stock availability)

Nylon tip

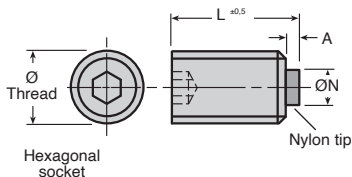

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-15%	On request

Part number	Ø Thread	Pitch	L	ØN	A	Stock*	Price each 1 to 5
NTM2-4	M2	0,4	4,0	0,8	0,8	✓	15,07 €
NTM2-5	M2	0,4	5,0	0,8	0,8	✓	13,58 €
NTM2-6	M2	0,4	6,0	0,8	0,8	✓	10,07 €
NTM2-7	M2	0,4	7,0	0,8	0,8	✓	22,60 €
NTM3-4	M3	0,5	4,0	1,6	0,8	✓	7,65 €
NTM3-5	M3	0,5	5,0	1,6	0,8	✓	5,73 €
NTM3-6	M3	0,5	6,0	1,6	0,8	✓	8,97 €
NTM4-5	M4	0,7	5,0	2,4	1,2	✓	7,14 €
NTM4-7	M4	0,7	7,0	2,4	1,2	✓	5,40 €
NTM4-11	M4	0,7	11,0	2,4	1,2	✓	6,74 €
NTM4-15	M4	0,7	15,0	2,4	1,2	✓	25,26 €
NTM5-7	M5	0,8	7,0	2,4	1,2	✓	17,12 €
NTM5-11	M5	0,8	11,0	2,4	1,2	✓	5,40 €
NTM5-15	M5	0,8	15,0	2,4	1,2	✓	8,79 €
NTM5-21	M5	0,8	21,0	2,4	1,2	✓	8,40 €
NTM6-7.5	M6	1,0	7,5	3,2	1,6	✓	6,74 €
NTM6-11.5	M6	1,0	11,5	3,2	1,6	✓	6,93 €
NTM6-17.5	M6	1,0	17,5	3,2	1,6	✓	12,19 €
NTM6-26.5	M6	1,0	26,5	3,2	1,6	✓	13,93 €
NTM10-14.5	M10	1,5	14,5	4,8	2,4	-	11,11 €
NTM10-22.5	M10	1,5	22,5	4,8	2,4	-	25,46 €

*Depending on availability - Dimensions in mm

Our other products



gt64r

Rotating bent lever with spring, increased fitting tolerances



RHTplss

High Temperature Castor, up to 200kg



BSM

Spring plunger with internal hexagonal socket, steel body, plastic pin



EP7

Electronic digital position indicator, 5 numbers




RCC_RCX

Spherical tilt washer - DIN6319, convex



RTL450

 Self-centering locking assembly, High torque



PM3

Worm and wheel set, Bronze



BOXdh

Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



PRF4590_E

Bracket for aluminium profile, PRF4590



BPLE

Ball transfer unit push fit, Light



VPRA_M

Handwheel with handle, Thermosetting plastic



VELprf

Clip-on base for hook-and-loop strip, Polyamide

Complementary products



NTMdl

Set screw delrin tip, Delrin-point



NTMbr

Set screw brass tip, Brass-point