


- Does not damage shafts
- Self-locking
- Nylon tip adapts to shaft and increases grip
- Materials :
Stainless steel
Nylon head (colour can vary depending on stock availability)

Nylon tip

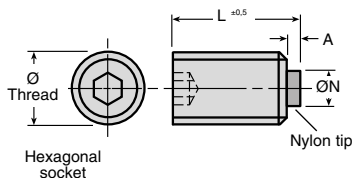

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Ø Thread	Pitch	L	ØN	A	Stock*	Price each 1 to 5
NTM2-4	M2	0,4	4,0	0,8	0,8	✓	15,07 €
NTM2-5	M2	0,4	5,0	0,8	0,8	✓	13,58 €
NTM2-6	M2	0,4	6,0	0,8	0,8	✓	10,07 €
NTM2-7	M2	0,4	7,0	0,8	0,8	✓	22,60 €
NTM3-4	M3	0,5	4,0	1,6	0,8	✓	7,65 €
NTM3-5	M3	0,5	5,0	1,6	0,8	✓	5,73 €
NTM3-6	M3	0,5	6,0	1,6	0,8	✓	8,97 €
NTM4-5	M4	0,7	5,0	2,4	1,2	✓	7,14 €
NTM4-7	M4	0,7	7,0	2,4	1,2	✓	5,40 €
NTM4-11	M4	0,7	11,0	2,4	1,2	✓	6,74 €
NTM4-15	M4	0,7	15,0	2,4	1,2	✓	25,26 €
NTM5-7	M5	0,8	7,0	2,4	1,2	✓	17,12 €
NTM5-11	M5	0,8	11,0	2,4	1,2	✓	5,40 €
NTM5-15	M5	0,8	15,0	2,4	1,2	✓	8,79 €
NTM5-21	M5	0,8	21,0	2,4	1,2	✓	8,40 €
NTM6-7.5	M6	1,0	7,5	3,2	1,6	✓	6,74 €
NTM6-11.5	M6	1,0	11,5	3,2	1,6	✓	6,93 €
NTM6-17.5	M6	1,0	17,5	3,2	1,6	✓	12,19 €
NTM6-26.5	M6	1,0	26,5	3,2	1,6	✓	13,93 €
NTM10-14.5	M10	1,5	14,5	4,8	2,4	-	11,11 €
NTM10-22.5	M10	1,5	22,5	4,8	2,4	-	25,46 €

*Depending on availability - Dimensions in mm

Our other products



Linear bearing, Light



Spring loaded plunger with ball tip, Stainless steel body



Support profile, Panel support



Female rod ends, Steel / steel - Economy range



T-Clip - Aluminium profile attachment, T-Clip



Hexagonal headed bolts, Steel class 8.8



Stainless steel articulated foot Ø50, Ø 50



Idler sprocket for slat top chain, Ranges 821 and 805



Stainless steel spur gear, Stainless steel



Machined plastic bevel gear, 1:1



Rounded end feather key, Stainless steel



Roll of hinge without pin, Plastic hinge

Complementary products



Set screw delrin tip, Delrin-point



Set screw brass tip, Brass-point