

NTM_{BR}

Blackened steel finish

- Material

Screw : steel (class 10.9)


Tip : brass

Info

- The tip is fitted into the screw.
- These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



Brass tip

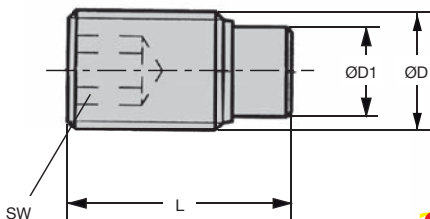

INCREASED STOCK


DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-25%	-45%	On request

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM4-6/BR	M4	2,5	6,5	2	✓	5,88 €
NTM4-10/BR	M4	2,5	10,5	2	✓	5,88 €
NTM4-16/BR	M4	2,5	16,5	2	-	6,07 €
NTM4-30/BR	M4	2,5	30,5	2	-	8,17 €
NTM4-40/BR	M4	2,5	40,5	2	-	8,32 €
NTM5-8/BR	M5	3	8,5	2,5	-	5,28 €
NTM5-12/BR	M5	3	12,5	2,5	✓	5,28 €
NTM5-20/BR	M5	3	20,5	2,5	✓	5,53 €
NTM5-30/BR	M5	3	30,5	2,5	✓	8,32 €
NTM5-40/BR	M5	3	40,5	2,5	-	8,43 €

*Depending on availability - Dimensions in mm

✓ INCREASED STOCK

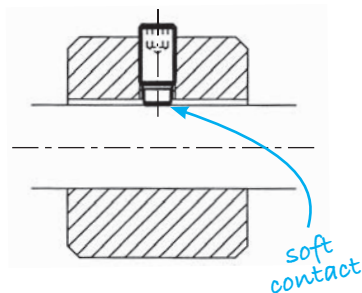

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM6-11/BR	M6	4,0	11,5	3	✓	5,28 €
NTM6-17/BR	M6	4,0	17,5	3	✓	5,28 €
NTM6-26/BR	M6	4,0	26,5	3	✓	5,53 €
NTM6-41/BR	M6	4,0	41,5	3	-	8,49 €
NTM6-51/BR	M6	4,0	51,5	3	-	8,63 €
NTM6-61/BR	M6	4,0	61,5	3	✓	8,67 €
NTM8-12/BR	M8	5,5	12,0	4	✓	5,48 €
NTM8-22/BR	M8	5,5	22,0	4	-	5,48 €
NTM8-32/BR	M8	5,5	32,0	4	✓	5,63 €
NTM8-52/BR	M8	5,5	52,0	4	-	8,79 €
NTM8-62/BR	M8	5,5	62,0	4	✓	8,92 €
NTM8-82/BR	M8	5,5	82,0	4	-	8,98 €
NTM10-14/BR	M10	7,0	14,0	5	✓	6,23 €
NTM10-18/BR	M10	7,0	18,0	5	-	6,23 €
NTM10-27/BR	M10	7,0	27,0	5	-	6,41 €
NTM10-37/BR	M10	7,0	37,0	5	-	6,77 €
NTM10-52/BR	M10	7,0	52,0	5	-	8,92 €
NTM10-62/BR	M10	7,0	62,0	5	-	9,08 €
NTM10-82/BR	M10	7,0	82,0	5	✓	9,23 €
NTM12-18/BR	M12	8,5	18,5	6	-	6,92 €
NTM12-22/BR	M12	8,5	22,5	6	-	6,92 €
NTM12-32/BR	M12	8,5	32,5	6	-	7,48 €
NTM12-42/BR	M12	8,5	42,5	6	-	8,07 €
NTM12-52/BR	M12	8,5	52,5	6	-	9,08 €
NTM12-62/BR	M12	8,5	62,5	6	-	9,27 €
NTM12-82/BR	M12	8,5	82,5	6	✓	9,53 €

*Depending on availability - Dimensions in mm

Our other products



DZY
Cylindrical stop, Steel



PRF JL5
Lip seal for panel,
Door seal - Ø 5mm



CF
Cam follower,
Standard - steel



PRES4HR
Manual workbench
press, Force up to
600kg



DOMI50
Connecting kits, XY
linking kit



DILC
Indexing plunger with
cam, with cam



PRF4545_P
Strip Aluminium
profile with
extendable slot, 45 x
45 mm



CLASS
Stainless steel
indexing handle -
male, Stainless steel



SUPccss
Self-centering
clamping hub
stainless steel, With



RT61ss
Self-centering locking
Assembly,
Medium/low torque



VTLF
3 lobed handle,
Polyamide - Brass



ETP
Modular handle for
aluminium profile,
Modular handle

Complementary products



NTMdl
Set screw delrin tip,
Delrin-point



NTM
Nylon tipped set
screw, Nylon-point