

# Cup point set screw



## HCss


## Stainless steel A2

- Conforms to DIN 916
- Material:  
Stainless steel 302/304 - A2
- Working temperature up to +430°C


### Info.

- Supplied by pack

Hexagonal socket

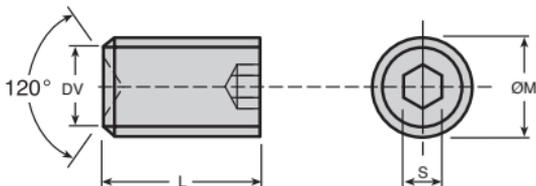

### Designer's Note

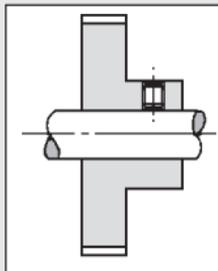

Bore or shaft diameter		Screw size
from Ø	to Ø (included)	ØT
Ø4	- Ø6	M3
Ø6	- Ø8	M3
Ø8	- Ø10	M3
Ø10	Ø12	M4
Ø12	- Ø17	M5
Ø17	- Ø22	M6
Ø22	- Ø30	M8
Ø30	- Ø44	M10
Ø44	- Ø58	M12

### DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Length			Qty. per packet	Stock*	Price per packet
	ØM	Pitch	L	DV	S			
HC2-3/SS/B	M2	0,40	3	1,0	0,9	200	✓	23,81 €
HC2-4/SS/B	M2	0,40	4	1,0	0,9	200	✓	25,36 €
HC2-5/SS/B	M2	0,40	5	1,0	0,9	200	✓	33,10 €
HC2-6/SS/B	M2	0,40	6	1,0	0,9	200	✓	21,75 €
HC2-10/SS/B	M2	0,40	10	1,0	0,9	500	-	38,02 €
HC2.5-5/SS/B	M2,5	0,45	5	1,2	1,3	200	-	On request
HC2.5-8/SS/B	M2,5	0,45	8	1,2	1,3	200	-	On request
HC2.5-10/SS/B	M2,5	0,45	10	1,2	1,3	200	-	On request

\*Depending on availability - Dimensions in mm

Part number	Thread		Length			Qty. per packet	Stock*	Price per packet
	ØM	Pitch	L	DV	S			
HC3-4/SS/B	M3	0,50	4	1,4	1,5	500	✓	14,70 €
HC3-5/SS/B	M3	0,50	5	1,4	1,5	500	✓	21,74 €
HC3-6/SS/B	M3	0,50	6	1,4	1,5	500	✓	12,13 €
HC3-8/SS/B	M3	0,50	8	1,4	1,5	500	✓	15,24 €
HC3-10/SS/B	M3	0,50	10	1,4	1,5	500	✓	22,30 €
HC3-12/SS/B	M3	0,50	12	1,4	1,5	500	-	17,81 €
HC3-16/SS/B	M3	0,50	16	1,4	1,5	500	-	22,22 €
HC3-20/SS/B	M3	0,50	20	1,4	1,5	500	✓	44,47 €
HC4-4/SS/B	M4	0,70	4	2,0	2,0	500	✓	11,08 €
HC4-5/SS/B	M4	0,70	5	2,0	2,0	500	✓	7,15 €
HC4-6/SS/B	M4	0,70	6	2,0	2,0	500	✓	10,95 €
HC4-8/SS/B	M4	0,70	8	2,0	2,0	500	-	8,25 €
HC4-10/SS/B	M4	0,70	10	2,0	2,0	500	✓	10,82 €
HC4-12/SS/B	M4	0,70	12	2,0	2,0	500	-	14,13 €
HC4-16/SS/B	M4	0,70	16	2,0	2,0	500	-	14,13 €
HC4-20/SS/B	M4	0,70	20	2,0	2,0	500	✓	40,96 €
HC5-5/SS/B	M5	0,80	5	2,5	2,5	500	✓	9,92 €
HC5-6/SS/B	M5	0,80	6	2,5	2,5	500	✓	16,97 €
HC5-8/SS/B	M5	0,80	8	2,5	2,5	500	✓	11,93 €
HC5-10/SS/B	M5	0,80	10	2,5	2,5	500	✓	11,75 €
HC5-12/SS/B	M5	0,80	12	2,5	2,5	500	✓	22,01 €
HC5-16/SS/B	M5	0,80	16	2,5	2,5	500	-	18,55 €
HC5-20/SS/B	M5	0,80	20	2,5	2,5	500	✓	22,41 €
HC5-25/SS/B	M5	0,80	25	2,5	2,5	200	-	43,87 €
HC5-30/SS/B	M5	0,80	30	2,5	2,5	200	✓	19,04 €
HC6-6/SS/B	M6	1,00	6	3,0	3,0	500	✓	20,34 €
HC6-8/SS/B	M6	1,00	8	3,0	3,0	500	✓	39,13 €
HC6-10/SS/B	M6	1,00	10	3,0	3,0	500	✓	28,83 €
HC6-12/SS/B	M6	1,00	12	3,0	3,0	500	✓	49,93 €
HC6-16/SS/B	M6	1,00	16	3,0	3,0	500	-	31,96 €
HC6-20/SS/B	M6	1,00	20	3,0	3,0	500	✓	49,52 €
HC6-25/SS/B	M6	1,00	25	3,0	3,0	200	✓	20,86 €
HC6-30/SS/B	M6	1,00	30	3,0	3,0	200	-	27,26 €
HC6-35/SS/B	M6	1,00	35	3,0	3,0	200	-	24,84 €
HC6-40/SS/B	M6	1,00	40	3,0	3,0	200	✓	31,53 €
HC8-16/SS/B	M8	1,25	16	5,0	4,0	200	✓	18,96 €
HC8-20/SS/B	M8	1,25	20	5,0	4,0	200	✓	22,26 €
HC8-25/SS/B	M8	1,25	25	5,0	4,0	200	-	27,19 €
HC8-30/SS/B	M8	1,25	30	5,0	4,0	200	✓	46,37 €
HC8-40/SS/B	M8	1,25	40	5,0	4,0	200	-	50,63 €
HC10-10/SS/B	M10	1,50	10	6,0	5,0	100	-	On request
HC10-16/SS/B	M10	1,50	16	6,0	5,0	100	-	17,93 €
HC10-20/SS/B	M10	1,50	20	6,0	5,0	100	✓	23,22 €
HC10-25/SS/B	M10	1,50	25	6,0	5,0	100	-	22,22 €
HC10-30/SS/B	M10	1,50	30	6,0	5,0	100	-	27,73 €
HC10-40/SS/B	M10	1,50	40	6,0	5,0	100	-	39,54 €
HC10-50/SS/B	M10	1,50	50	6,0	5,0	100	-	59,38 €

\*Depending on availability - Dimensions in mm

## NTM<sub>DL</sub>

## Blackened steel finish


- Materiel :  
Screw : steel (class 10.9)  
Tip : Delrin

### Info

- The tip is fitted into the screw.
- These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



Delrin tip

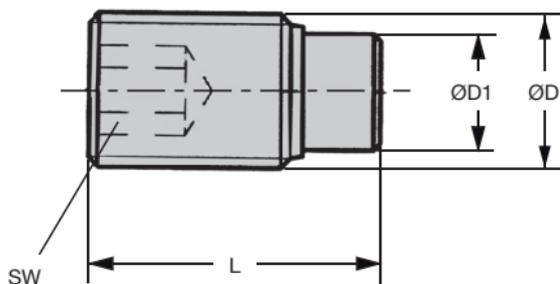


### DISCOUNTS

Qty	1+	6+	30+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-25%	-45%	On request

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM4-7/DL	M4	2	7	2	✓	3,69 €
NTM4-9/DL	M4	2	9	2	✓	3,69 €
NTM4-11/DL	M4	2	11	2	✓	3,69 €
NTM4-13/DL	M4	2	13	2	✓	3,64 €
NTM4-17/DL	M4	2	17	2	✓	3,64 €
NTM4-31/DL	M4	2	31	2	✓	8,89 €
NTM4-41/DL	M4	2	41	2	-	9,02 €
NTM5-9/DL	M5	3	9	2,5	✓	3,42 €
NTM5-11/DL	M5	3	11	2,5	-	3,42 €
NTM5-13/DL	M5	3	13	2,5	-	3,42 €
NTM5-17/DL	M5	3	17	2,5	✓	3,42 €
NTM5-21/DL	M5	3	21	2,5	-	3,69 €
NTM5-31/DL	M5	3	31	2,5	-	9,49 €
NTM5-41/DL	M5	3	41	2,5	-	9,66 €

\*Depending on availability - Dimensions in mm

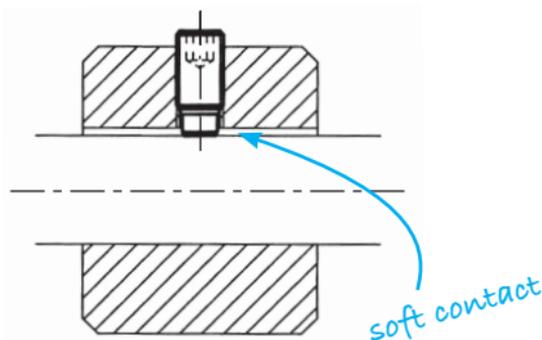


Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM6-11/DL	M6	3,5	11,3	3	✓	3,42 €
NTM6-13/DL	M6	3,5	13,3	3	✓	3,42 €
NTM6-17/DL	M6	3,5	17,3	3	-	3,69 €
NTM6-21/DL	M6	3,5	21,3	3	✓	3,69 €
NTM6-26/DL	M6	3,5	26,3	3	✓	3,88 €
NTM6-41/DL	M6	3,5	41,3	3	-	9,80 €
NTM6-51/DL	M6	3,5	51,3	3	-	9,94 €
NTM6-61/DL	M6	3,5	61,3	3	-	10,07 €
NTM8-13/DL	M8	5	13,6	4	-	3,88 €
NTM8-17/DL	M8	5	17,6	4	✓	3,88 €
NTM8-21/DL	M8	5	21,6	4	-	3,88 €
NTM8-26/DL	M8	5	26,6	4	✓	4,16 €
NTM8-33/DL	M8	5	33,6	4	✓	4,74 €
NTM8-51/DL	M8	5	51,6	4	-	9,49 €
NTM8-61/DL	M8	5	61,6	4	-	9,66 €
NTM8-81/DL	M8	5	81,6	4	✓	9,80 €
NTM10-18/DL	M10	6,5	17,9	5	-	4,60 €
NTM10-22/DL	M10	6,5	21,9	5	-	4,79 €
NTM10-27/DL	M10	6,5	26,9	5	-	4,80 €
NTM10-34/DL	M10	6,5	33,9	5	-	5,54 €
NTM10-42/DL	M10	6,5	41,9	5	-	6,39 €
NTM10-52/DL	M10	6,5	51,9	5	-	9,66 €
NTM10-62/DL	M10	6,5	61,9	5	-	9,86 €
NTM10-82/DL	M10	6,5	81,9	5	-	9,94 €
NTM12-22/DL	M12	8	22,1	6	-	5,39 €
NTM12-27/DL	M12	8	27,1	6	✓	5,54 €
NTM12-34/DL	M12	8	34,1	6	-	6,07 €
NTM12-42/DL	M12	8	42,1	6	-	6,79 €
NTM12-52/DL	M12	8	52,1	6	-	7,84 €
NTM12-62/DL	M12	8	62,1	6	-	10,07 €
NTM12-82/DL	M12	8	82,1	6	-	10,28 €

\*Depending on availability - Dimensions in mm

- Materiel :  
Screw : steel (class 10.9)  
Tip : brass

### Info

- The tip is fitted into the screw.  
These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.

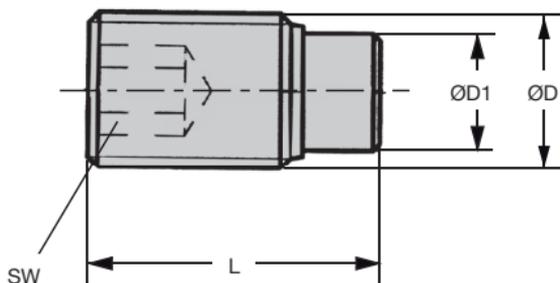


### DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-25%	-45%	On request

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM4-6/BR	M4	2,5	6,5	2	✓	7,22 €
NTM4-10/BR	M4	2,5	10,5	2	✓	7,22 €
NTM4-16/BR	M4	2,5	16,5	2	-	7,45 €
NTM4-30/BR	M4	2,5	30,5	2	-	10,06 €
NTM4-40/BR	M4	2,5	40,5	2	-	10,25 €
NTM5-8/BR	M5	3	8,5	2,5	-	6,51 €
NTM5-12/BR	M5	3	12,5	2,5	✓	6,51 €
NTM5-20/BR	M5	3	20,5	2,5	-	6,76 €
NTM5-30/BR	M5	3	30,5	2,5	-	10,25 €
NTM5-40/BR	M5	3	40,5	2,5	-	10,42 €

\*Depending on availability - Dimensions in mm

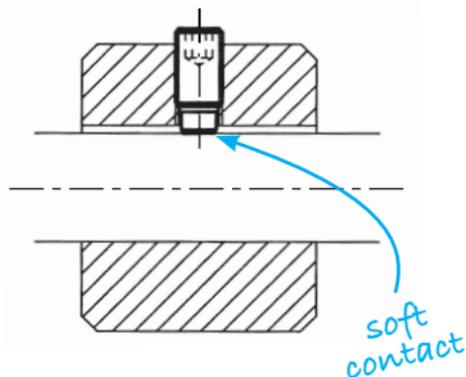


Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM6-11/BR	M6	4,0	11,5	3	✓	6,51 €
NTM6-17/BR	M6	4,0	17,5	3	✓	6,51 €
NTM6-26/BR	M6	4,0	26,5	3	✓	6,76 €
NTM6-41/BR	M6	4,0	41,5	3	-	10,43 €
NTM6-51/BR	M6	4,0	51,5	3	-	10,65 €
NTM6-61/BR	M6	4,0	61,5	3	-	10,64 €
NTM8-12/BR	M8	5,5	12,0	4	✓	6,75 €
NTM8-22/BR	M8	5,5	22,0	4	✓	6,75 €
NTM8-32/BR	M8	5,5	32,0	4	✓	6,93 €
NTM8-52/BR	M8	5,5	52,0	4	-	10,84 €
NTM8-62/BR	M8	5,5	62,0	4	-	11,01 €
NTM8-82/BR	M8	5,5	82,0	4	-	11,08 €
NTM10-14/BR	M10	7,0	14,0	5	-	7,70 €
NTM10-18/BR	M10	7,0	18,0	5	-	7,70 €
NTM10-27/BR	M10	7,0	27,0	5	-	7,86 €
NTM10-37/BR	M10	7,0	37,0	5	-	8,30 €
NTM10-52/BR	M10	7,0	52,0	5	-	11,01 €
NTM10-62/BR	M10	7,0	62,0	5	-	11,20 €
NTM10-82/BR	M10	7,0	82,0	5	✓	11,37 €
NTM12-18/BR	M12	8,5	18,5	6	-	8,46 €
NTM12-22/BR	M12	8,5	22,5	6	-	8,46 €
NTM12-32/BR	M12	8,5	32,5	6	-	9,24 €
NTM12-42/BR	M12	8,5	42,5	6	-	9,94 €
NTM12-52/BR	M12	8,5	52,5	6	-	11,20 €
NTM12-62/BR	M12	8,5	62,5	6	-	11,42 €
NTM12-82/BR	M12	8,5	82,5	6	-	11,73 €

\*Depending on availability - Dimensions in mm

- Does not damage shafts
- Self-locking
- Nylon tip adapts to shaft and increases grip
- Materials :  
 Stainless steel  
 Nylon head (colour can vary depending on stock availability)

Nylon tip

stainless steel

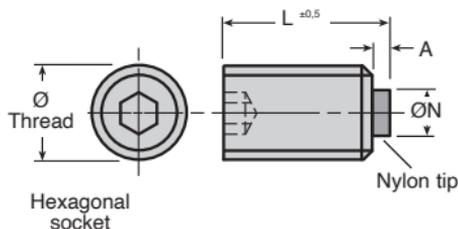

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-15%	On request

Part number	Ø Thread	Pitch	L	ØN	A	Stock*	Price each 1 to 5
NTM2-4	M2	0,4	4,0	0,8	0,8	✓	23,87 €
NTM2-5	M2	0,4	5,0	0,8	0,8	✓	27,02 €
NTM2-6	M2	0,4	6,0	0,8	0,8	✓	21,17 €
NTM2-7	M2	0,4	7,0	0,8	0,8	-	On request
NTM3-4	M3	0,5	4,0	1,6	0,8	✓	10,52 €
NTM3-5	M3	0,5	5,0	1,6	0,8	✓	7,82 €
NTM3-6	M3	0,5	6,0	1,6	0,8	✓	17,45 €
NTM4-5	M4	0,7	5,0	2,4	1,2	✓	8,66 €
NTM4-7	M4	0,7	7,0	2,4	1,2	✓	16,11 €
NTM4-11	M4	0,7	11,0	2,4	1,2	✓	13,77 €
NTM4-15	M4	0,7	15,0	2,4	1,2	✓	30,64 €
NTM5-7	M5	0,8	7,0	2,4	1,2	✓	20,76 €
NTM5-11	M5	0,8	11,0	2,4	1,2	✓	10,22 €
NTM5-15	M5	0,8	15,0	2,4	1,2	✓	15,24 €
NTM5-21	M5	0,8	21,0	2,4	1,2	✓	10,19 €
NTM6-7.5	M6	1,0	7,5	3,2	1,6	✓	15,22 €
NTM6-11.5	M6	1,0	11,5	3,2	1,6	✓	11,09 €
NTM6-17.5	M6	1,0	17,5	3,2	1,6	✓	14,79 €
NTM6-26.5	M6	1,0	26,5	3,2	1,6	✓	16,90 €
NTM10-14.5	M10	1,5	14,5	4,8	2,4	-	13,47 €
NTM10-22.5	M10	1,5	22,5	4,8	2,4	-	33,98 €

\*Depending on availability - Dimensions in mm