

## NTM<sub>BR</sub>

## Blackened steel finish

### - Material

Screw : steel (class 10.9)


Tip : brass

### Info

- The tip is fitted into the screw.
- These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



Brass tip

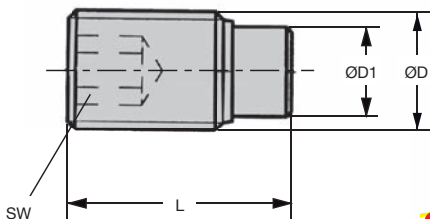

**INCREASED STOCK**


### DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-25%	-45%	On request

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM4-6/BR	M4	2,5	6,5	2	✓	5,88 €
NTM4-10/BR	M4	2,5	10,5	2	✓	5,88 €
NTM4-16/BR	M4	2,5	16,5	2	-	6,07 €
NTM4-30/BR	M4	2,5	30,5	2	-	8,17 €
NTM4-40/BR	M4	2,5	40,5	2	-	8,32 €
NTM5-8/BR	M5	3	8,5	2,5	-	5,28 €
NTM5-12/BR	M5	3	12,5	2,5	✓	5,28 €
NTM5-20/BR	M5	3	20,5	2,5	✓	5,53 €
NTM5-30/BR	M5	3	30,5	2,5	✓	8,32 €
NTM5-40/BR	M5	3	40,5	2,5	-	8,43 €

\*Depending on availability - Dimensions in mm

**✓ INCREASED STOCK**

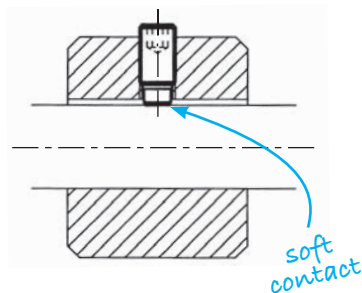

Part number	ØD	ØD1	L	SW	Stock*	Price each 1 to 19
NTM6-11/BR	M6	4,0	11,5	3	✓	5,28 €
NTM6-17/BR	M6	4,0	17,5	3	✓	5,28 €
NTM6-26/BR	M6	4,0	26,5	3	✓	5,53 €
NTM6-41/BR	M6	4,0	41,5	3	-	8,49 €
NTM6-51/BR	M6	4,0	51,5	3	-	8,63 €
NTM6-61/BR	M6	4,0	61,5	3	✓	8,67 €
NTM8-12/BR	M8	5,5	12,0	4	✓	5,48 €
NTM8-22/BR	M8	5,5	22,0	4	-	5,48 €
NTM8-32/BR	M8	5,5	32,0	4	✓	5,63 €
NTM8-52/BR	M8	5,5	52,0	4	-	8,79 €
NTM8-62/BR	M8	5,5	62,0	4	✓	8,92 €
NTM8-82/BR	M8	5,5	82,0	4	-	8,98 €
NTM10-14/BR	M10	7,0	14,0	5	✓	6,23 €
NTM10-18/BR	M10	7,0	18,0	5	-	6,23 €
NTM10-27/BR	M10	7,0	27,0	5	-	6,41 €
NTM10-37/BR	M10	7,0	37,0	5	-	6,77 €
NTM10-52/BR	M10	7,0	52,0	5	-	8,92 €
NTM10-62/BR	M10	7,0	62,0	5	-	9,08 €
NTM10-82/BR	M10	7,0	82,0	5	✓	9,23 €
NTM12-18/BR	M12	8,5	18,5	6	-	6,92 €
NTM12-22/BR	M12	8,5	22,5	6	-	6,92 €
NTM12-32/BR	M12	8,5	32,5	6	-	7,48 €
NTM12-42/BR	M12	8,5	42,5	6	-	8,07 €
NTM12-52/BR	M12	8,5	52,5	6	-	9,08 €
NTM12-62/BR	M12	8,5	62,5	6	-	9,27 €
NTM12-82/BR	M12	8,5	82,5	6	✓	9,53 €

\*Depending on availability - Dimensions in mm

## Our other products



BMM

Knurled knob - male,  
Knurled



MNPOT

Potentiometer,



T5P\_T10P

Connecting plate for T  
type timing belts, T10



SUA4\_L

Chain link, Steel



T10\_30\_AL

T type timing pulley,  
Economy range - T10  
aluminium



CNA-CNG

Right angled  
mounting plate, Right  
angled mounting  
plate for ball jo...



EFTC

Fixing support,  
Stainless steel



OP3\_14\_06

Reducing sleeve for  
OP indicators,  
Reduction socket



MDB\_MTB

Moulded plastic bevel  
gear (nylon), 3:1



CHT

Asynchronous AC  
Motor, 0.18 to 0.55kW



SBS\_L

Chain link, Stainless  
steel



BC3

Panamech, Multi-  
Beam stainless steel,  
Stainless steel - with  
clampin...

## Complementary products



NTMdl

Set screw delrin tip,  
Delrin-point



NTM

Nylon tipped set  
screw, Nylon-point