

# Digital position indicator

OP7DX  
OP7SX


5 digit display

- 5 digit display (red digit displays tenths, black digit displays hundredth), displays up to 99999
- Shaft driven position indicator
- 5 digit display to display and control a linear movement (or an angle) that is driven by a rotating control shaft.
- Non-flammable shock-proof polycarbonate housing
- Max temperature: 80 °C
- Color : orange
- Height of digits: 6 mm with
- Standard shaft hole 20H7, other holes smaller than 20mm with reducing sleeve.

## Avantages

- Interchangeable with the OP6 but with a smaller, more compact shape.
- The overall height of the OP7 fitted with the OP6-FL locking clamp is the same as the OP6

Stainless steel version on request

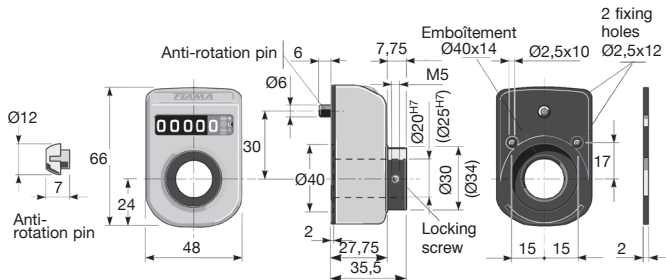


# OP7DX OP7SX

## Options


- Version with stainless steel parts available

## Assembly

- Insert the indicator on to the shaft ensuring that the anti-rotation pin is inserted into the 6mm hole that should have been drilled previously. Reset the display to zero and secure the fixing screw.

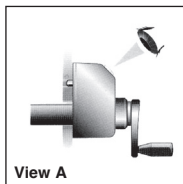

View A

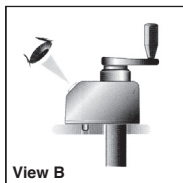

View B

## DISCOUNTS

Qty	1+	5+	+10
Disc.	List -15%	On request	

Part number	View	Pitch (mm)	Display after one turn (mm)	Max. speed (rpm)	Counting direction	Price each 1 to 4
OP7-A10-DX	A	1	001 0	300	clockwise	71,50 €
OP7-A20-DX	A	2	002 0	300	clockwise	71,50 €
OP7-A40-DX	A	4	004 0	200	clockwise	71,50 €
OP7-A50-DX	A	5	005 0	200	clockwise	71,50 €
OP7-A100-DX	A	10	010 0	150	clockwise	71,50 €
OP7-B10-DX	B	1	001 0	300	clockwise	71,50 €
OP7-B20-DX	B	2	002 0	300	clockwise	71,50 €
OP7-B40-DX	B	4	004 0	200	clockwise	71,50 €
OP7-B50-DX	B	5	005 0	200	clockwise	71,50 €
OP7-B100-DX	B	10	010 0	150	clockwise	71,50 €
OP7-A10-SX	A	1	001 0	300	anticlockwise	71,50 €
OP7-A20-SX	A	2	002 0	300	anticlockwise	71,50 €
OP7-A40-SX	A	4	004 0	200	anticlockwise	71,50 €
OP7-A50-SX	A	5	005 0	200	anticlockwise	71,50 €
OP7-A100-SX	A	10	010 0	150	anticlockwise	71,50 €
OP7-B10-SX	B	1	001 0	300	anticlockwise	71,50 €
OP7-B20-SX	B	2	002 0	300	anticlockwise	71,50 €
OP7-B40-SX	B	4	004 0	200	anticlockwise	71,50 €
OP7-B50-SX	B	5	005 0	200	anticlockwise	71,50 €
OP7-B100-SX	B	10	010 0	150	anticlockwise	71,50 €

Dimensions in mm

## Our other products



SUA4\_L

Chain link, Steel



AC144

Strike for toggle latch,  
22mm



T5\_11

T type timing pulley,  
T5 aluminium



AT10courroie

AT type timing belt,  
AT10 Steel cored  
polyurethane



METC

Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



BPVMss

Stainless steel  
miniature ball transfer  
unit, Miniature to  
screw



VTLF

3 lobed handle,  
Polyamide - Brass



RBNpl

Swivel castor with  
double brake, Steel -  
rubber



PRF-SRA-78

Lock for aluminium  
profile, Quick fitting,



BLHM50

Right angled gearbox,  
double output shafts,



RCX-6

Spherical tilt washer -  
DIN6319, concave



M0

Worm and wheel set,  
Non hardened steel

## Complementary products



OP3\_14\_06

Reducing sleeve for  
OP indicators,  
Reduction socket



OPFL\_OPPM

Numerical counter  
accessories, Locking  
clamp



OP6

Mechanical digital  
position indicator, 5  
numbers



OPFL\_OPPM

Numerical counter  
accessories,  
Operating knob