

Self locking counter nut

DIN Sta

PAL



For axial locking

- Self locking nut
- Conforms to DIN 7967
- Stainless steel A2

Advantages

- Self locking on threaded shafts

stainless
steel

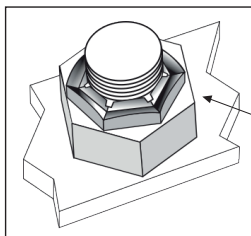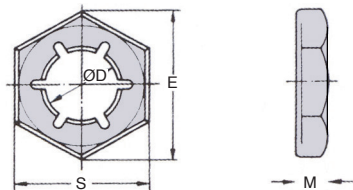

Used as a
counter nut

Typical application

DISCOUNTS

Qty	1+	6+	11+
Disc.	List	-10%	On request

Part number	For thread				Quantity per box	Stock*	Price each 1 to 5
	ØD	M	E	S			
PAL-M5/B	M5	5	8,79	8	500	✓	18,48 €
PAL-M6/B	M6	6	11,05	10	200	✓	8,77 €
PAL-M8/B	M8	8	14,38	13	100	✓	11,73 €
PAL-M10/B	M10	10	16,64	15	100	✓	6,59 €
PAL-M12/B	M12	12	20,03	18	100	-	8,43 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



FDSQ

Flexible drive shaft, Masterflex® Steel, with PVC casing



TPEpd

Castor for aluminium profile, Swivel with brake




PF40

Worm and wheel gear reducer, up to 18 Nm



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm

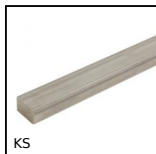


KS

Keysteel, Stainless steel - Keystock



PRS30

Stainless steel articulated foot Ø30, Ø 30

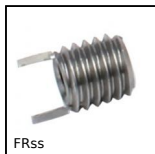

FRss

Stainless steel thread inserts, Stainless steel



MFB_MHB

Moulded plastic bevel gear (nylon), 4:1



UCFL

Cast iron flanged bearing, Cast iron



VELM4


Screw-on base for hook-and-loop strip,



WW20


Drylin® W slide, slide assembly

 Complementary products



CXS

 External circlip
DIN471, external DIN
471



CYS

Internal circlip
DIN472, internal DIN
472



BFA

Shaft locking washer,
E clip