

# Self locking counter nut

DIN Sta

## PAL



## For axial locking

- Self locking nut
- Conforms to DIN 7967
- Stainless steel A2

### Advantages

- Self locking on threaded shafts

stainless steel

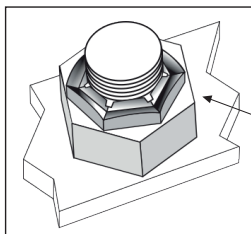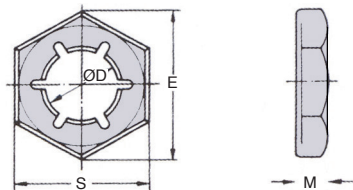

Used as a counter nut

Typical application

### DISCOUNTS

Qty	1+	6+	11+
Disc.	List	-10%	On request

Part number	For thread				Quantity per box	Stock*	Price each 1 to 5
	ØD	M	E	S			
PAL-M5/B	M5	5	8,79	8	500	✓	18,48 €
PAL-M6/B	M6	6	11,05	10	200	✓	8,77 €
PAL-M8/B	M8	8	14,38	13	100	✓	11,73 €
PAL-M10/B	M10	10	16,64	15	100	✓	6,59 €
PAL-M12/B	M12	12	20,03	18	100	-	8,43 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



CFF\_SS

Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...



B\_ECO

Eco. range steel bevel gear, 1:1



UCF

Cast iron flange bearing unit, Cast iron



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



MDB\_MTB

Moulded plastic bevel gear (nylon), 3:1



DCG

Suction cup, 2.5 bellows, natural rubber



G-ECO

Eco range Spur gear, Steel C45



CHAR7530

Spring hinge, welded



PSG2

Spur gear - precision range, Case hardened steel 20NCD2



LVT

Miniature motorised actuator 2A, 2 ampers



IN1


Internal gear, Steel 20NCD2



CAP882


Flexible slat top chain acetal, Large range 882
 
## Complementary products



CXS

 External circlip DIN471, external DIN 471



CYS

Internal circlip DIN472, internal DIN 472



BFA

Shaft locking washer, E clip