

# Self locking counter nut

DIN Sta

## PAL



## For axial locking

- Self locking nut
- Conforms to DIN 7967
- Stainless steel A2

### Advantages

- Self locking on threaded shafts

stainless  
steel

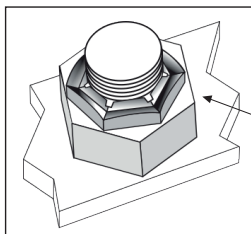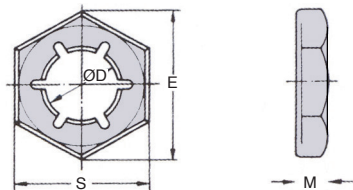

Used as a  
counter nut

Typical application

### DISCOUNTS

Qty	1+	6+	11+
Disc.	List	-10%	On request

Part number	For thread				Quantity per box	Stock*	Price each 1 to 5
	ØD	M	E	S			
PAL-M5/B	M5	5	8,79	8	500	✓	18,48 €
PAL-M6/B	M6	6	11,05	10	200	✓	8,77 €
PAL-M8/B	M8	8	14,38	13	100	✓	11,73 €
PAL-M10/B	M10	10	16,64	15	100	✓	6,59 €
PAL-M12/B	M12	12	20,03	18	100	-	8,43 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



G4

Steel spur gear, Steel  
20NCD2



GAL\_25

Ø25 conveyor roller,  
Without ball bearing



 
GE

Toggle latches,  
Standard



DIL

Lever operated  
locking bolt, lever  
clamp



H2

Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)




PM3

Worm and wheel set,  
Hardened steel



OP7

Mechanical digital  
position indicator, 5  
numbers

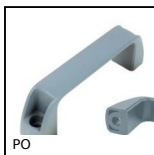


PO

Pull handle - Multi-  
sector, Smooth hole



BOX-TOR-H

 Box set of Nitrile O-  
rings in nitrile, 3.00 x  
3.00



G1

Steel spur gear, Steel  
20NCD2



CHB


Worm and wheel gear  
reducer, up to 73 Nm



R203


Die spring ISO10243,  
Light

## Complementary products

 

CXS

 External circlip  
DIN471, external DIN  
471



CYS

Internal circlip  
DIN472, internal DIN  
472



BFA

Shaft locking washer,  
E clip